


# Varistar 19" Shelf, Stationary, 75 kg

## Data Solutions

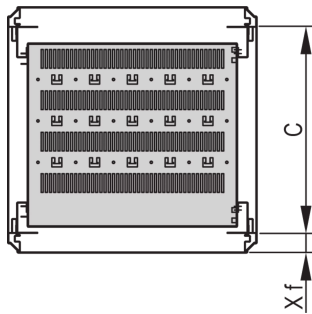

Varistar 19" Shelf, Stationary, 75 kg.

## CERTIFICATIONS



## FEATURES

Static load-carrying capacity 75 kg

St, 1.5 mm

Incl. GND/grounding

Width 495 mm

For mounting on four 19" panel/slide mounts

## SPECIFICATIONS

**Product Type:** Shelf

**Material:** Steel

Table 1/2

| Catalog Number | Width | Depth | Package Quantity | Color | Color Code | Finish |
|----------------|-------|-------|------------------|-------|------------|--------|
|----------------|-------|-------|------------------|-------|------------|--------|

|           |       |       |   |            |          |               |
|-----------|-------|-------|---|------------|----------|---------------|
| 22130-309 | 495mm |       | 1 | Light Grey | RAL 7035 | Powder Coated |
| 21130-302 | 495mm |       | 1 | Black Grey | RAL 7021 | Powder Coated |
| 21130-303 | 495mm |       | 1 | Black Grey | RAL 7021 | Powder Coated |
| 21130-304 | 495mm | 800mm | 1 | Black Grey | RAL 7021 | Powder Coated |
| 21130-305 | 495mm | 800mm | 1 | Black Grey | RAL 7021 | Powder Coated |
| 21130-309 | 495mm |       | 1 | Black Grey | RAL 7021 | Powder Coated |
| 22130-302 | 495mm |       | 1 | Light Grey | RAL 7035 | Powder Coated |
| 22130-303 | 495mm |       | 1 | Light Grey | RAL 7035 | Powder Coated |
| 22130-304 | 495mm | 800mm | 1 | Light Grey | RAL 7035 | Powder Coated |
| 22130-305 | 495mm | 800mm | 1 | Light Grey | RAL 7035 | Powder Coated |

| Table 2/2      |        |        |                |
|----------------|--------|--------|----------------|
| Catalog Number | Height | Length | Type           |
| 22130-309      | 740mm  | 682mm  | Full Depth     |
| 21130-302      | 400mm  | 342mm  | Recessed Depth |
| 21130-303      | 500mm  | 442mm  | Full Depth     |
| 21130-304      | 600mm  | 642mm  | Recessed Depth |
| 21130-305      | 700mm  | 642mm  | Full Depth     |
| 21130-309      | 740mm  | 682mm  | Full Depth     |
| 22130-302      | 400mm  | 342mm  | Recessed Depth |
| 22130-303      | 500mm  | 442mm  | Full Depth     |

| Catalog Number | Height | Length | Type           |
|----------------|--------|--------|----------------|
| 22130-304      | 600mm  | 642mm  | Recessed Depth |
| 22130-305      | 700mm  | 642mm  | Full Depth     |

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE