


Universal Busbar Support, 30–125 mm Busbar Width, 5 mm Busbar Thickness

CATALOG NUMBER

UBS4-5T

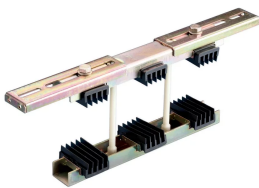

CERTIFICATIONS



FEATURES

Universal fixing system

Installs quickly and easily

Extremely robust construction

Adjustable arms for easy mounting

Halogen free insulators

PRODUCT ATTRIBUTES

Article Number: 551020

Material: Steel;Glass Fibre Reinforced Polyamide

Max Working Voltage, IEC (Ui): 1000;1500

Working Temperature: -40 to 130 °C

Complies With: IEC® 60439.1;IEC® 61439.1;IEC® 60695-2-11 (Glow Wire Test 960 °C)

Flammability Rating: UL® 94V-0

Typical Application Current Rating: 3500 A

Busbars per Phase: 1 - 4

Busbar Width: 30 - 125 mm

Busbar Thickness: 5 mm

Width (W): 375 - 575 mm

A: 350 - 550 mm


B: 176 mm

C: 307 mm

D: 110 mm

Unit Weight: 2.22 kg

DIAGRAMS

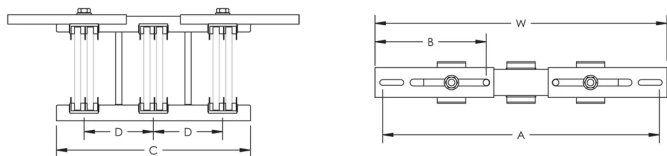

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE