


FGBS Fiberglass Braided Sleeve

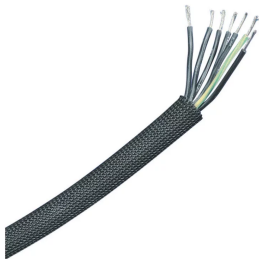

CERTIFICATIONS



FEATURES

Fiberglass impregnated with high temperature silicone varnish

Resistant to high temperature

Thermal insulation and mechanical protection

Halogen free

SPECIFICATIONS

Working Temperature: -70 to 300 °C

Material: Fiberglass

Flammability Rating: UL® 1441 VW-1

Table 1/1

Catalog Number	Article Number	Diameter	Color	Length	Unit Weight
FGBS8	556210	8 mm	Black	100m	0.01 kg
FGBS4	556200	4 mm	Black	100m	0.01 kg

Catalog Number	Article Number	Diameter	Color	Length	Unit Weight
FGBS12	556230	12 mm	Black	100m	0.02 kg
FGBS10	556220	10 mm	Black	100m	0.02 kg
FGBS15	556240	16 mm	Black	100m	0.03 kg
FGBS20	556250	20 mm	White	50m	0.04 kg

ADDITIONAL PRODUCT DETAILS

Unit weight is per meter (3.28').

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE