


# EuropacPRO Cover Plate for Bolting to Side Panel

## Power Utilities

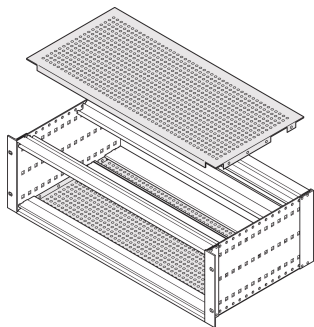

A cover plate is used for electromagnetic shielding or as mechanical protection. The cover can be screwed onto the side panel.

## CERTIFICATIONS



## FEATURES

For variable positioning of horizontal rails e.g. for PCBs with standard formats

Perforation degree 58%

Suitable for use with all horizontal rails

## SPECIFICATIONS

Table 1/2

| Catalog Number | Rack Width | Depth  | Package Quantity | Product Family | Product Type | Type       |
|----------------|------------|--------|------------------|----------------|--------------|------------|
| 24560-064      | 42 HP      | 175 mm | 1                | EuropacPRO     | Cover Plate  | Perforated |
| 24560-065      | 42 HP      | 235 mm | 1                | EuropacPRO     | Cover Plate  | Perforated |

| CatalogNumber | Rack Width | Depth     | Package Quantity | Product Family | Product Type | Type       |
|---------------|------------|-----------|------------------|----------------|--------------|------------|
| 24560-066     | 42 HP      | 295 mm    | 1                | EuropacPRO     | Cover Plate  | Perforated |
| 24560-071     | 63 HP      | 175 mm    | 1                | EuropacPRO     | Cover Plate  | Perforated |
| 24560-072     | 63 HP      | 235 mm    | 1                | EuropacPRO     | Cover Plate  | Perforated |
| 24560-073     | 63 HP      | 295 mm    | 1                | EuropacPRO     | Cover Plate  | Perforated |
| 24560-078     | 84 HP      | 175 mm    | 1                | EuropacPRO     | Cover Plate  | Perforated |
| 24560-079     | 84 HP      | 235 mm    | 1                | EuropacPRO     | Cover Plate  | Perforated |
| 24560-080     | 84 HP      | 295 mm    | 1                | EuropacPRO     | Cover Plate  | Perforated |
| 24560-081     | 84 HP      | 355 mm    | 1                | EuropacPRO     | Cover Plate  | Perforated |
| 24560-082     | 84 HP      | 415 mm    | 1                | EuropacPRO     | Cover Plate  | Perforated |
| 24560-083     | 84 HP      | 475 mm    | 1                | EuropacPRO     | Cover Plate  | Perforated |
| 24560-061     | 42 HP      | 275 mm    | 1                | EuropacPRO     | Cover Plate  | Perforated |
| 24560-062     | 63 HP      | 275 mm    | 1                | EuropacPRO     | Cover Plate  | Perforated |
| 24560-063     | 84 HP      | 275 mm    | 1                | EuropacPRO     | Cover Plate  | Perforated |
| 24579-090     | 42 HP      | 277.75 mm | 1                | EuropacPRO     | Cover Plate  | Perforated |
| 24579-092     | 84 HP      | 277.75 mm | 1                | EuropacPRO     | Cover Plate  | Perforated |

Table 2/2

| Catalog Number | Works With | Package Unit | Torque  |
|----------------|------------|--------------|---------|
| 24560-064      | Subracks   | Pair         | 2.1 N·m |
| 24560-065      | Subracks   | Pair         | 2.1 N·m |

| Catalog Number | Works With | Package Unit | Torque  |
|----------------|------------|--------------|---------|
| 24560-066      | Subracks   | Pair         | 2.1 N·m |
| 24560-071      | Subracks   | Pair         | 2.1 N·m |
| 24560-072      | Subracks   | Pair         | 2.1 N·m |
| 24560-073      | Subracks   | Pair         | 2.1 N·m |
| 24560-078      | Subracks   | Pair         | 2.1 N·m |
| 24560-079      | Subracks   | Pair         | 2.1 N·m |
| 24560-080      | Subracks   | Pair         | 2.1 N·m |
| 24560-081      | Subracks   | Pair         | 2.1 N·m |
| 24560-082      | Subracks   | Pair         | 2.1 N·m |
| 24560-083      | Subracks   | Pair         | 2.1 N·m |
| 24560-061      | Subracks   | Pair         |         |
| 24560-062      | Subracks   | Pair         |         |
| 24560-063      | Subracks   | Pair         |         |
| 24579-090      | Subracks   | Pair         | 2.1 N·m |
| 24579-092      | Subracks   | Pair         | 2.1 N·m |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**