


# AMC Front Panel With Pull Handle

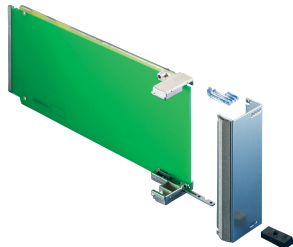

AdvancedMC Front Panel including EMC gasket for AMC.0 Rev. 2.0 Modules.

## CERTIFICATIONS



## FEATURES

In accordance with AMC.0 R2.0 specification

Front panel for pull-handle mechanism (with cut-outs for light pipe)

For the use together with the AMC Pull-handle mechanism, AMC.0 R2.0

## SPECIFICATIONS

**Accessory Type:** Front panel

**Product Type:** Front Panel


Table 1/2

| Catalog Number | Height (H) | Rack Width | Design Feature | Material | Finish     | Package Quantity |
|----------------|------------|------------|----------------|----------|------------|------------------|
| 30849-682      | 73.8mm     | 6HP        | Full-Size      | Aluminum | Passivated | 1                |
| 30849-670      | 148.8mm    | 4HP        |                | Aluminum | Passivated | 1                |
| 30849-694      | 148.8mm    | 6HP        | Full-Size      | Aluminum | Passivated | 1                |

| CatalogNumber | Height (H) | Rack Width | Design Feature | Material        | Finish     | Package Quantity |
|---------------|------------|------------|----------------|-----------------|------------|------------------|
| 30849-403     | 73.8mm     | 4HP        | Mid-Size       | Stainless Steel |            | 1                |
| 30849-404     | 73.8mm     | 6HP        | Full-Size      | Stainless Steel |            | 1                |
| 30849-406     | 148.8mm    | 4HP        | Mid-Size       | Stainless Steel |            | 1                |
| 30849-407     | 148.8mm    | 6HP        | Full-Size      | Stainless Steel |            | 1                |
| 30849-402     | 73.8mm     | 3HP        | Compact        | Stainless Steel |            | 1                |
| 30849-658     | 73.8mm     | 4HP        | Mid-Size       | Aluminum        | Passivated | 1                |

Table 2/2

| Catalog Number | Front Finish | Rear Finish | Depth (D) | Width (W) | Quick Ship |
|----------------|--------------|-------------|-----------|-----------|------------|
| 30849-682      | Raw          | Raw         | 2.5mm     | 29mm      | No         |
| 30849-670      | Raw          | Raw         | 2.5mm     | 19mm      | No         |
| 30849-694      | Raw          | Raw         | 2.5mm     | 29mm      | No         |
| 30849-403      | Raw          | Raw         | 1mm       | 19mm      | No         |
| 30849-404      | Raw          | Raw         | 1mm       | 29mm      | No         |
| 30849-406      | Raw          | Raw         | 1mm       | 19mm      | No         |
| 30849-407      | Raw          | Raw         | 1mm       | 29mm      | No         |
| 30849-402      | Raw          | Raw         | 1mm       | 13.9mm    | No         |
| 30849-658      | Raw          | Raw         | 2.5mm     | 19mm      | No         |

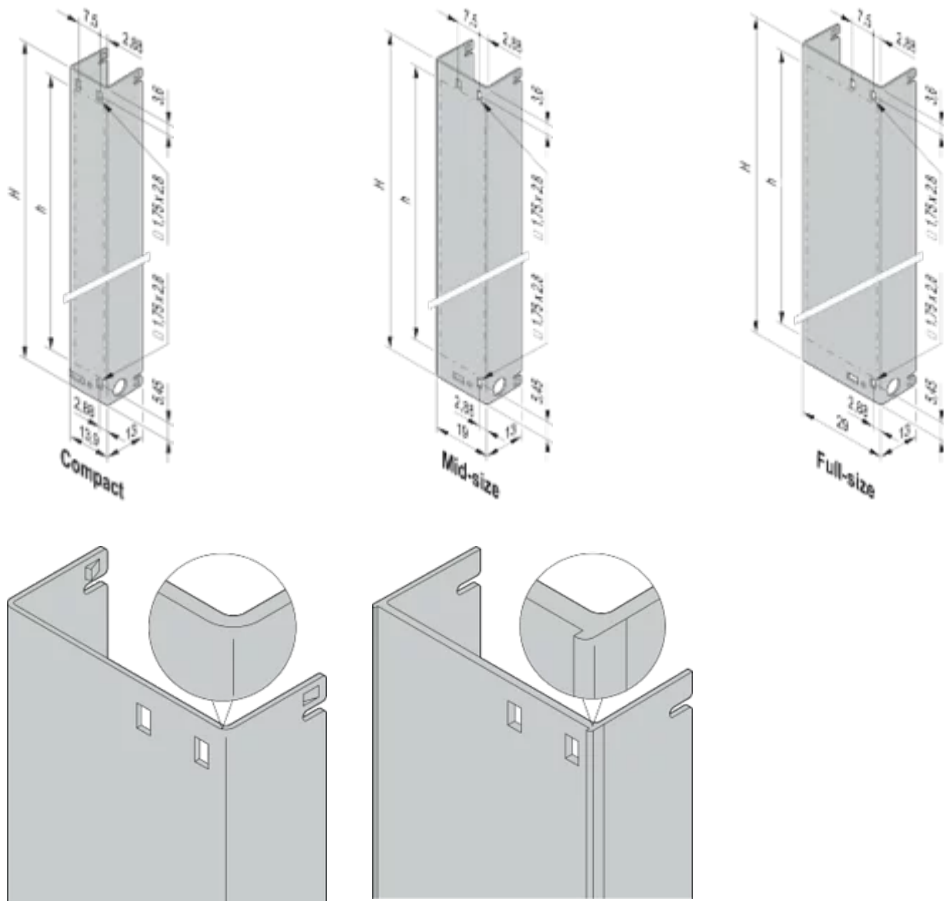

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Europe**

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Asia**

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Middle East & India**

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**