


ATCA Front Panel, St, Reinforced, With Spring Loading

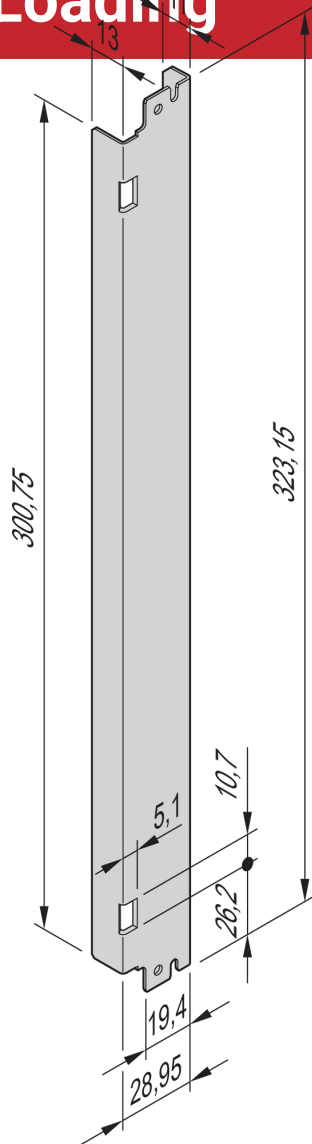

AdvancedTCA front panel for spring-loaded IEA handle with die-cast end piece.

CERTIFICATIONS



FEATURES

Configuration: Front panel with IEA handle (with/without spring loading)

SPECIFICATIONS

- Depth (D):

1mm
- Rack Width:

6HP
- Rack Height:

8U
- Accessory Type:

Front panel
- Product Type:


Front Panel
- Material:

Stainless Steel

Table 1/2						
Catalog Number	Package Quantity	Handle Type	Front Finish	Rear Finish	Height (H)	Width (W)
31596-791	1	Plunger	Raw	Raw	323.15mm	29mm
31596-792	1	Lever	Raw	Raw	323.15mm	29mm

Table 2/2	
Catalog Number	Quick Ship
31596-791	No
31596-792	No

DIAGRAMS

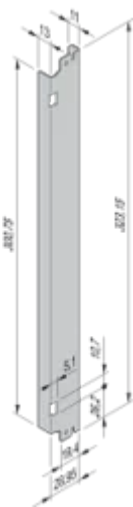

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE