


# Varistar CP Mobile Frame

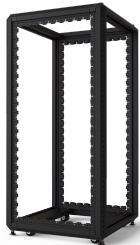

Varistar welded steel frame for static load requirements. For 19", ETSI or mounting plate integration. For mobile applications.

## FEATURES

Welded, finish powder-coated, black gray, RAL 7021

## SPECIFICATIONS

|                      |                    |
|----------------------|--------------------|
| <b>Dynamic Load:</b> | 1000kg             |
| <b>Static Load:</b>  | 1600kg             |
| <b>Product Type:</b> | Cabinet/Rack Frame |
| <b>Material:</b>     | Steel              |

Table 1/2

| Catalog Number | Rack Height | Height | Width | Depth  | Package Quantity | Color      |
|----------------|-------------|--------|-------|--------|------------------|------------|
| 20630-252      | 52U         | 2450mm | 600mm | 1100mm | 1                | Black Grey |
| 20630-255      | 52U         | 2450mm | 800mm | 1100mm | 1                | Black Grey |
| 20630-231      | 42U         | 2000mm | 600mm | 1100mm | 1                | Black Grey |
| 20630-232      | 42U         | 2000mm | 600mm | 1200mm | 1                | Black Grey |
| 20630-237      | 42U         | 2000mm | 800mm | 1100mm | 1                | Black Grey |
| 20630-238      | 42U         | 2000mm | 800mm | 1200mm | 1                | Black Grey |

| CatalogNumber | Rack Height | Height | Width | Depth  | Package Quantity | Color      |
|---------------|-------------|--------|-------|--------|------------------|------------|
| 20630-243     | 47U         | 2200mm | 600mm | 1100mm | 1                | Black Grey |
| 20630-244     | 47U         | 2200mm | 600mm | 1200mm | 1                | Black Grey |
| 20630-249     | 47U         | 2200mm | 800mm | 1100mm | 1                | Black Grey |
| 20630-250     | 47U         | 2200mm | 800mm | 1200mm | 1                | Black Grey |
| 20630-193     | 24U         | 1200mm | 600mm | 600mm  | 1                | Black Grey |
| 20630-194     | 24U         | 1200mm | 600mm | 800mm  | 1                | Black Grey |
| 20630-199     | 24U         | 1200mm | 800mm | 600mm  | 1                | Black Grey |
| 20630-200     | 24U         | 1200mm | 800mm | 800mm  | 1                | Black Grey |
| 20630-203     | 29U         | 1400mm | 600mm | 600mm  | 1                | Black Grey |
| 20630-204     | 29U         | 1400mm | 600mm | 800mm  | 1                | Black Grey |
| 20630-207     | 29U         | 1400mm | 800mm | 600mm  | 1                | Black Grey |
| 20630-208     | 29U         | 1400mm | 800mm | 800mm  | 1                | Black Grey |
| 20630-211     | 33U         | 1600mm | 600mm | 600mm  | 1                | Black Grey |
| 20630-212     | 33U         | 1600mm | 600mm | 800mm  | 1                | Black Grey |
| 20630-215     | 33U         | 1600mm | 800mm | 600mm  | 1                | Black Grey |
| 20630-216     | 33U         | 1600mm | 800mm | 800mm  | 1                | Black Grey |
| 20630-219     | 38U         | 1800mm | 600mm | 600mm  | 1                | Black Grey |
| 20630-220     | 38U         | 1800mm | 600mm | 800mm  | 1                | Black Grey |

| CatalogNumber | Rack Height | Height | Width | Depth  | Package Quantity | Color      |
|---------------|-------------|--------|-------|--------|------------------|------------|
| 20630-223     | 38U         | 1800mm | 800mm | 600mm  | 1                | Black Grey |
| 20630-224     | 38U         | 1800mm | 800mm | 800mm  | 1                | Black Grey |
| 20630-227     | 42U         | 2000mm | 600mm | 600mm  | 1                | Black Grey |
| 20630-228     | 42U         | 2000mm | 600mm | 800mm  | 1                | Black Grey |
| 20630-229     | 42U         | 2000mm | 600mm | 900mm  | 1                | Black Grey |
| 20630-230     | 42U         | 2000mm | 600mm | 1000mm | 1                | Black Grey |
| 20630-233     | 42U         | 2000mm | 800mm | 600mm  | 1                | Black Grey |
| 20630-234     | 42U         | 2000mm | 800mm | 800mm  | 1                | Black Grey |
| 20630-235     | 42U         | 2000mm | 800mm | 900mm  | 1                | Black Grey |
| 20630-236     | 42U         | 2000mm | 800mm | 1000mm | 1                | Black Grey |
| 20630-239     | 47U         | 2200mm | 600mm | 600mm  | 1                | Black Grey |
| 20630-240     | 47U         | 2200mm | 600mm | 800mm  | 1                | Black Grey |
| 20630-241     | 47U         | 2200mm | 600mm | 900mm  | 1                | Black Grey |
| 20630-242     | 47U         | 2200mm | 600mm | 1000mm | 1                | Black Grey |
| 20630-245     | 47U         | 2200mm | 800mm | 600mm  | 1                | Black Grey |
| 20630-246     | 47U         | 2200mm | 800mm | 800mm  | 1                | Black Grey |
| 20630-247     | 47U         | 2200mm | 800mm | 900mm  | 1                | Black Grey |
| 20630-248     | 47U         | 2200mm | 800mm | 1000mm | 1                | Black Grey |

| CatalogNumber | Rack Height | Height | Width | Depth  | Package Quantity | Color      |
|---------------|-------------|--------|-------|--------|------------------|------------|
| 20630-195     | 24U         | 1200mm | 600mm | 900mm  | 1                | Black Grey |
| 20630-196     | 24U         | 1200mm | 600mm | 1000mm | 1                | Black Grey |
| 20630-201     | 24U         | 1200mm | 800mm | 900mm  | 1                | Black Grey |
| 20630-202     | 24U         | 1200mm | 800mm | 1000mm | 1                | Black Grey |
| 20630-205     | 29U         | 1400mm | 600mm | 900mm  | 1                | Black Grey |
| 20630-206     | 29U         | 1400mm | 600mm | 1000mm | 1                | Black Grey |
| 20630-209     | 29U         | 1400mm | 800mm | 900mm  | 1                | Black Grey |
| 20630-210     | 29U         | 1400mm | 800mm | 1000mm | 1                | Black Grey |
| 20630-213     | 33U         | 1600mm | 600mm | 900mm  | 1                | Black Grey |
| 20630-214     | 33U         | 1600mm | 600mm | 1000mm | 1                | Black Grey |
| 20630-217     | 33U         | 1600mm | 800mm | 900mm  | 1                | Black Grey |
| 20630-218     | 33U         | 1600mm | 800mm | 1000mm | 1                | Black Grey |
| 20630-221     | 38U         | 1800mm | 600mm | 900mm  | 1                | Black Grey |
| 20630-222     | 38U         | 1800mm | 600mm | 1000mm | 1                | Black Grey |
| 20630-225     | 38U         | 1800mm | 800mm | 900mm  | 1                | Black Grey |
| 20630-226     | 38U         | 1800mm | 800mm | 1000mm | 1                | Black Grey |
| 20630-251     | 52U         | 2450mm | 600mm | 1000mm | 1                | Black Grey |
| 20630-254     | 52U         | 2450mm | 800mm | 1000mm | 1                | Black Grey |

| CatalogNumber | Rack Height | Height | Width | Depth  | Package Quantity | Color      |
|---------------|-------------|--------|-------|--------|------------------|------------|
| 20630-253     | 52U         | 2450mm | 600mm | 1200mm | 1                | Black Grey |
| 20630-256     | 52U         | 2450mm | 800mm | 1200mm | 1                | Black Grey |

Table 2/2

| Catalog Number | Color Code | Complies With               | Frame Material | Type   | Works With  | Quick Ship |
|----------------|------------|-----------------------------|----------------|--------|-------------|------------|
| 20630-252      | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-255      | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-231      | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-232      | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-237      | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-238      | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-243      | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-244      | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-249      | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-250      | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-193      | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-194      | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-199      | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-200      | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |

| CatalogNumber | Color Code | Complies With               | Frame Material | Type   | Works With  | Quick Ship |
|---------------|------------|-----------------------------|----------------|--------|-------------|------------|
| 20630-203     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-204     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-207     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-208     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-211     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-212     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-215     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-216     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-219     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-220     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-223     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-224     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-227     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-228     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-229     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-230     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-233     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-234     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |

| CatalogNumber | Color Code | Complies With               | Frame Material | Type   | Works With  | Quick Ship |
|---------------|------------|-----------------------------|----------------|--------|-------------|------------|
| 20630-235     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-236     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-239     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-240     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-241     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-242     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-245     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-246     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-247     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-248     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-195     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-196     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-201     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-202     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-205     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-206     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-209     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-210     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |

| CatalogNumber | Color Code | Complies With               | Frame Material | Type   | Works With  | Quick Ship |
|---------------|------------|-----------------------------|----------------|--------|-------------|------------|
| 20630-213     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-214     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-217     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-218     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-221     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-222     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-225     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-226     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-251     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-254     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-253     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |
| 20630-256     | RAL 7021   | IEC 61587-1,<br>IEC 61587-3 | Steel          | Mobile | Varistar CP | No         |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**