

# 107 Wraparound Strap for CPVC Pipe



## CERTIFICATIONS



## FEATURES

Includes flared edges to protect piping

Rated for use with CPVC fire sprinkler pipe

Includes mounting screw

## SPECIFICATIONS

**Finish:** Pregalvanized

**Material:** Steel

Table 1/2


Catalog Number	Article Number	NB/DN	Outer Diameter (OD)	Hole Size (HS)	A	B
1070125EG	597818	32	42.2 mm	5.8 mm	41.3 mm	77.8 mm
1070200EG	597821	50	60.3 mm	5.8 mm	47.6 mm	93.7 mm
1070100EG	597817	25	33.7 mm	5.8 mm	36.5 mm	68.3 mm

CatalogNumber	Article Number	NB/DN	Outer Diameter (OD)	Hole Size (HS)	A	B
1070150EG	597819	40	48.3 mm	5.8 mm	44.5 mm	84.1 mm
1070075EG	597816	20	26.9 mm	5.8 mm	31.8 mm	60.3 mm

Table 2/2

Catalog Number	Article Number	C	Hanger Spacing
1070125EG	597818	30.2 mm	1.95 m Max
1070200EG	597821	30.2 mm	2.4 m Max
1070100EG	597817	30.2 mm	1.8 m Max
1070150EG	597819	30.2 mm	2.1 m Max
1070075EG	597816	30.2 mm	1.65 m Max

## DIAGRAMS

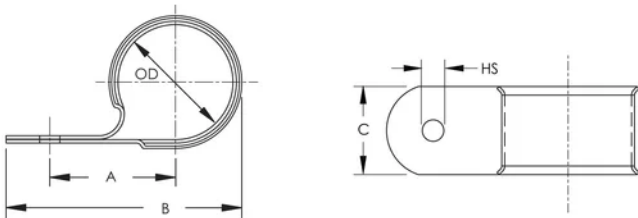

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

