

# SC Cable Snap Clip



## FEATURES

Easily supports cable and plastic conduit from flanges

Requires only a hammer to install

## SPECIFICATIONS

**Finish:** nVent CADDY Armour

**Material:** Spring Steel


Table 1/1

Catalog Number	Article Number	Flange Thickness (FT)	Outer Diameter (OD)	Thickness (T)
24SC1011	187550	2 - 4 mm	10 - 11 mm	0.6 mm
24SC1214	187570	2 - 4 mm	12 - 14 mm	0.6 mm
24SC1518	187590	2 - 4 mm	15 - 18 mm	0.6 mm
24SC1518R25	191003	2 - 4 mm	15 - 18 mm	0.6 mm
24SC1924	187610	2 - 4 mm	19 - 24 mm	0.6 mm
24SC1924R25	191004	2 - 4 mm	19 - 24 mm	0.6 mm

Catalog Number	Article Number	Flange Thickness (FT)	Outer Diameter (OD)	Thickness (T)
24SC2530	187630	2 - 4 mm	25 - 30 mm	0.6 mm
24SC2530R25	191005	2 - 4 mm	25 - 30 mm	0.6 mm
24SC67	187510	2 - 4 mm	6 - 7 mm	0.6 mm
24SC78	187710	2 - 4 mm	7 - 8 mm	0.6 mm
24SC89	187530	2 - 4 mm	8 - 9 mm	0.6 mm
24SC910	187750	2 - 4 mm	9 - 10 mm	0.6 mm
47SC1011	187540	4 - 7 mm	10 - 11 mm	0.6 mm
47SC1214	187560	4 - 7 mm	12 - 14 mm	0.6 mm
47SC1518	187580	4 - 7 mm	15 - 18 mm	0.6 mm
47SC1518R25	191009	4 - 7 mm	15 - 18 mm	0.6 mm
47SC1924	187600	4 - 7 mm	19 - 24 mm	0.6 mm
47SC1924R25	191010	4 - 7 mm	19 - 24 mm	0.6 mm
47SC2530	187620	4 - 7 mm	25 - 30 mm	0.6 mm
47SC2530R25	191011	4 - 7 mm	25 - 30 mm	0.6 mm
47SC67	187500	4 - 7 mm	6 - 7 mm	0.6 mm
47SC78	187720	4 - 7 mm	7 - 8 mm	0.6 mm
47SC89	187520	4 - 7 mm	8 - 9 mm	0.6 mm
47SC910	187760	4 - 7 mm	9 - 10 mm	0.6 mm

Catalog Number	Article Number	Flange Thickness (FT)	Outer Diameter (OD)	Thickness (T)
812SC1011	187660	8 - 12 mm	10 - 11 mm	0.6 mm
812SC1214	187670	8 - 12 mm	12 - 14 mm	0.6 mm
812SC1518	187680	8 - 12 mm	15 - 18 mm	0.6 mm
812SC1518R25	191015	8 - 12 mm	15 - 18 mm	0.6 mm
812SC1924	187690	8 - 12 mm	19 - 24 mm	0.6 mm
812SC1924R25	191016	8 - 12 mm	19 - 24 mm	0.6 mm
812SC2530	187700	8 - 12 mm	25 - 30 mm	0.6 mm
812SC2530R25	191017	8 - 12 mm	25 - 30 mm	0.6 mm
812SC67	187640	8 - 12 mm	6 - 7 mm	0.6 mm
812SC78	187730	8 - 12 mm	7 - 8 mm	0.6 mm
812SC89	187650	8 - 12 mm	8 - 9 mm	0.6 mm
812SC910	187770	8 - 12 mm	9 - 10 mm	0.6 mm

## DIAGRAMS

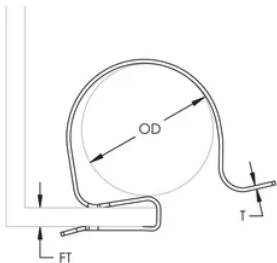

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause

product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

**Europe**

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**

