


# Copper Busbars, WO60

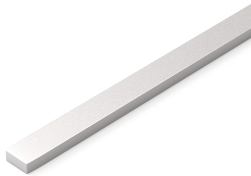

Standard tin-plated Cu busbars used together with busbar supports.

## INDUSTRY STANDARDS

---

UL

CSA

GL

## FEATURES

---

Description: Tin-plated Cu busbars. The Cu busbar is effectively protected against aggressive media.

Material: Cu-ETP R300 (EN13601), tinned

Length: 2400 mm

Pack quantity: 1 pc.

Approvals: CSA, UL, GL

## SPECIFICATIONS

Table 1/1						
Catalog Number	Height	Width	Depth	Material	Finish	Cross Section
01618	5mm	12mm	2400mm	Copper	Tinned	60mm <sup>2</sup>
01619	5mm	15mm	2400mm	Copper	Tinned	75mm <sup>2</sup>
01620	5mm	20mm	2400mm	Copper	Tinned	100mm <sup>2</sup>
01621	5mm	25mm	2400mm	Copper	Tinned	125mm <sup>2</sup>
01623	10mm	12mm	2400mm	Copper	Tinned	120mm <sup>2</sup>
01622	5mm	30mm	2400mm	Copper	Tinned	150mm <sup>2</sup>
01624	10mm	20mm	2400mm	Copper	Tinned	200mm <sup>2</sup>
01625	10mm	30mm	2400mm	Copper	Tinned	300mm <sup>2</sup>

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**