


# CS480 Straight Tube

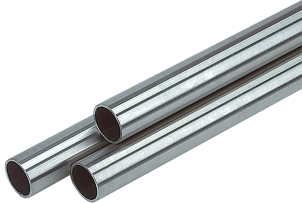

CS480 Straight Tube provides structural integrity and acts as conduit for equipment wiring.

## INDUSTRY STANDARDS

---

IEC 60529, IP66

## FEATURES

---

Wall thickness 3.6-mm

Outer diameter of 48.3-mm

Assembled CS480 HMI Arm System has a max weight load of 89.6 lb. (40.7 kg)

SPECIFICATIONS

**Finish:** Polished  
**Material:** Stainless Steel 304

Table 1/1					
Catalog Number	Height	Width	Depth	Thickness	Quick Ship
CCSS48T100	1000mm	48mm	48mm	3.6mm	No
CCSS48T125	1250mm	48mm	48mm	3.6mm	No
CCSS48T150	1500mm	48mm	48mm	3.6mm	No
CCSS48T25	250mm	48mm	48mm	3.6mm	No
CCSS48T50	500mm	48mm	48mm	3.6mm	No
CCSS48T75	750mm	48mm	48mm	3.6mm	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE