

# Drive Pin



Drive pins transfer forces between the wedge pins and the piston of the pin driver.

## FEATURES

Stamped with appropriate reinforcing bar size

Designed to withstand the forces required for assembly

Easily replaced when worn

## SPECIFICATIONS

**Material:** Steel

Table 1/2

Catalog Number	Article Number	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter 1 (Ø1)	Diameter 2 (Ø2)
ML515	145830	12 mm	#4	10M	22 mm	13 mm
ML516	145840	16 mm	#5	15M	22 mm	13 mm
ML517	145850	20 mm	#6	20M	22 mm	15 mm

Table 2/2


Catalog Number	Article Number	Length 1 (L1)	Length 2 (L2)	Unit Weight
ML515	145830	30 mm	10 mm	0.05 kg

Catalog Number	Article Number	Length 1 (L1)	Length 2 (L2)	Unit Weight
ML516	145840	25 mm	10 mm	0.05 kg
ML517	145850	20 mm	10 mm	0.07 kg

### ADDITIONAL PRODUCT DETAILS

Prior to installation, please read and understand the detailed instructions and safety notices provided in the nVent LENTON Quick Wedge Operator's Manual.

### DIAGRAMS

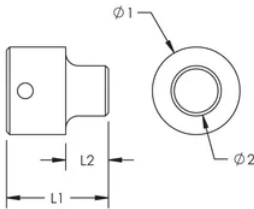

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

#### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

#### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

#### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**