


19" Front Panel, Plain

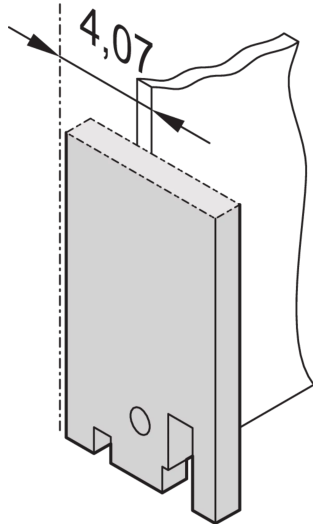

Front panel without or with SUB-D-, ST type 3- or FDDI cut-out.

CERTIFICATIONS



FEATURES

19" Front Panel without Cutout

SPECIFICATIONS

Depth:	2.5mm
Material:	Aluminum
Accessory Type:	Front panel
Product Type:	Front Panel

Table 1/2

Catalog Number	Rack Height	Rack Width	Package Quantity	Front Finish	Rear Finish	Color Code
30118-328	3U	4HP	1	Painted	Conductive	RAL 7035

CatalogNumber	Rack Height	Rack Width	Package Quantity	Front Finish	Rear Finish	Color Code
30118-329	3U	7HP	1	Painted	Conductive	RAL 7035
30118-330	3U	14HP	1	Painted	Conductive	RAL 7035
30118-331	3U	28HP	1	Painted	Conductive	RAL 7035

Table 2/2				
Catalog Number	Finish	Height	Width	Quick Ship
30118-328	Powder Coated	128.4mm	19.98mm	No
30118-329	Powder Coated	128.4mm	35.22mm	No
30118-330	Powder Coated	128.4mm	70.78mm	No
30118-331	Powder Coated	128.4mm	141.9mm	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE