


# CompacPRO Front/Rear Panel, With Hidden Fixing

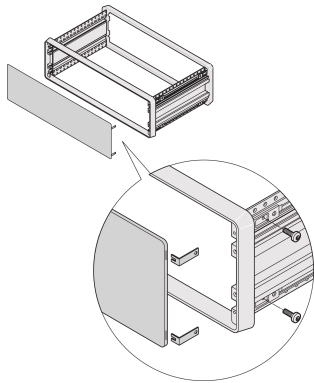

The front panel for CompacPRO Case mounts to the frame of the case. The front panel has no visible screws and can be used for front foil.

## CERTIFICATIONS



## FEATURES

Al panel, 2.5 mm

## SPECIFICATIONS

<b>Material:</b>	Aluminum
<b>Finish:</b>	Anodized
<b>Accessory Type:</b>	Front panel
<b>Product Type:</b>	Front Panel

Table 1/2

Catalog Number	Rack Height	Height	Rack Width	Width	Package Quantity	Front Finish
24575-115	3U	128.4mm	28HP	167.5mm	1	Anodized

CatalogNumber	Rack Height	Height	Rack Width	Width	Package Quantity	Front Finish
24575-035	2U	84mm	42HP	238.7mm	1	Anodized
24575-135	3U	128.4mm	42HP	238.7mm	1	Anodized
24575-075	2U	84mm	84HP	452.1mm	1	Anodized
24575-235	4U	172.9mm	42HP	238.7mm	1	Anodized
24575-155	3U	128.4mm	63HP	345.4mm	1	Anodized
24575-175	3U	128.4mm	84HP	452.1mm	1	Anodized
24575-255	4U	172.9mm	63HP	345.4mm	1	Anodized
24575-275	4U	172.9mm	84HP	452.1mm	1	Anodized
24575-455	6U	261.8mm	63HP	345.4mm	1	Anodized
24575-475	6U	261.8mm	84HP	452.1mm	1	Anodized

Table 2/2

Catalog Number	Rear Finish	Treated Edges	Depth	Quick Ship
24575-115	Anodized	No	2.5mm	No
24575-035	Anodized	No	2.5mm	No
24575-135	Anodized	No	2.5mm	No
24575-075	Anodized	No	2.5mm	No
24575-235	Anodized	No	2.5mm	No
24575-155	Anodized	No	2.5mm	No
24575-175	Anodized	No	2.5mm	No

Catalog Number	Rear Finish	Treated Edges	Depth	Quick Ship
24575-255	Anodized	No	2.5mm	No
24575-275	Anodized	No	2.5mm	No
24575-455	Anodized	No	2.5mm	No
24575-475	Anodized	No	2.5mm	No

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**