


U-profile Front Panel, Shieldable, D-Sub Cutouts

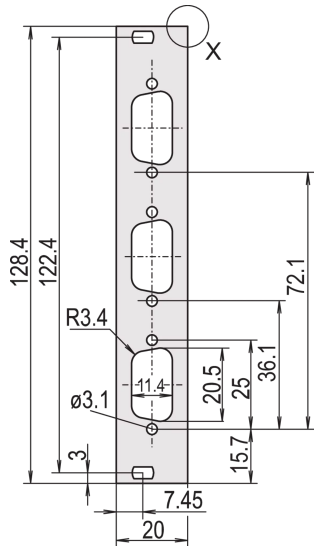

U-profile front panel with cutout for D-Sub connectors.
Shieldable for textile EMC gasket.

CERTIFICATIONS



FEATURES

U-profile, front panel, Al, 2.5 mm, front anodized, rear conductive

For EMC textile gasket

SPECIFICATIONS

Depth (D):	2.5mm
Rack Height:	3U
Rack Width:	4HP
Material:	Aluminum
Finish:	Anodized; Passivated
Accessory Type:	Front panel
Product Type:	Front Panel
Type:	Front Panel without Handle

Table 1/2

Catalog Number	Package Quantity	Mounting	Gasket Type	Front Finish	Rear Finish	Number of Pins
30849-751	1	Screw-on Front	Textile EMC	Anodized	Conductive	(3) 9
30849-752	1	Screw-on Front	Textile EMC	Anodized	Conductive	(1) 15
30849-750	1	Screw-on Front	Textile EMC	Anodized	Conductive	(2) 9
30849-754	1	Screw-on Front	Textile EMC	Anodized	Conductive	(1) 25
30849-755	1	Screw-on Front	Textile EMC	Anodized	Conductive	(2) 25
30849-753	1	Screw-on Front	Textile EMC	Anodized	Conductive	(2) 15
30849-749	1	Screw-on Front	Textile EMC	Anodized	Conductive	(1) 9

Table 2/2

Catalog Number	Treated Edges	Complies With	Height (H)	Width (W)	Quick Ship
30849-751	No	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	No
30849-752	No	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	No
30849-750	No	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	No
30849-754	No	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	No
30849-755	No	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	No
30849-753	No	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	No
30849-749	No	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	No

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

DIAGRAMS

