


# Varistar CP Double Glazed Door, IP 20, 3-Point Locking

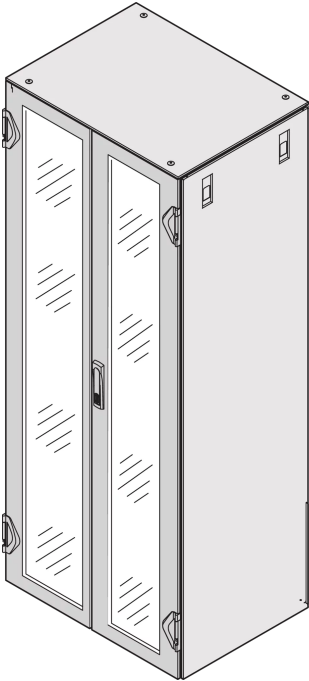

## FEATURES

---

Lever handle with key insert (2 keys)

Frame, St, 1.5 mm

Opening angle 180°

Security glass, 6 mm

Can be retrofitted with DIN profile half cylinder

Ingress protection class IP 20

Standard fitting, lock on right-hand door

## SPECIFICATIONS

---

<b>Locking Type:</b>	3-Point Locking
<b>Product Type:</b>	Cabinet Door
<b>Protection Rating:</b>	IP20
<b>Material:</b>	Steel

Table 1/2

Catalog Number	Rack Height	Height	Width	Package Quantity	Color	Color Code
21630-686	24U	1200mm	600mm	1	Black Grey	RAL 7021
21630-687	24U	1200mm	800mm	1	Black Grey	RAL 7021
21630-688	29U	1400mm	600mm	1	Black Grey	RAL 7021
21630-689	29U	1400mm	800mm	1	Black Grey	RAL 7021
21630-690	33U	1600mm	600mm	1	Black Grey	RAL 7021
21630-691	33U	1600mm	800mm	1	Black Grey	RAL 7021
21630-692	38U	1800mm	600mm	1	Black Grey	RAL 7021
21630-693	38U	1800mm	800mm	1	Black Grey	RAL 7021
21630-694	42U	2000mm	600mm	1	Black Grey	RAL 7021
21630-695	42U	2000mm	800mm	1	Black Grey	RAL 7021
21630-696	47U	2200mm	600mm	1	Black Grey	RAL 7021
21630-697	47U	2200mm	800mm	1	Black Grey	RAL 7021

Table 2/2

Catalog Number	Finish	Type	Quick Ship
21630-686	Powder Coated	Glass Double Door	No
21630-687	Powder Coated	Glass Double Door	No
21630-688	Powder Coated	Glass Double Door	No
21630-689	Powder Coated	Glass Double Door	No

Catalog Number	Finish	Type	Quick Ship
21630-690	Powder Coated	Glass Double Door	No
21630-691	Powder Coated	Glass Double Door	No
21630-692	Powder Coated	Glass Double Door	No
21630-693	Powder Coated	Glass Double Door	No
21630-694	Powder Coated	Glass Double Door	No
21630-695	Powder Coated	Glass Double Door	No
21630-696	Powder Coated	Glass Double Door	No
21630-697	Powder Coated	Glass Double Door	No

## ADDITIONAL PRODUCT DETAILS

---

Perforated Varistar CP glass double door with 3-point locking for applications with IP 20 protection.

24U - 33U IP20 doors have 2 hinges, 38U - 52U IP20 doors have 3 hinges to ensure robust IP20 closing structures for taller cabinets

Please order lever handle 24630003 and the DIN lock separately if you want to replace the 1333 DIN lock lever handle.

Please purchase the grounding kit separately.

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations

+1.763.422.2661

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**