


# Varistar CP Top Rear Panel, Shortened

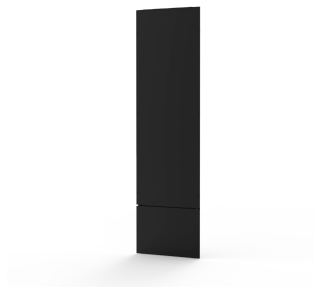

Shortened Rear Panel available for IP20, IP55 applications.

Shortened rear panels ensure efficient cable management.

## FEATURES

Screw fixed, Robust and Single person mountable Side Panel

Height of connection plate 400 mm

## SPECIFICATIONS

**Product Type:** Cabinet Door

**Protection Rating:** IP55

**Material:** Steel

Table 1/2

Catalog Number	Rack Height	Height	Width	Package Quantity	Color	Color Code
21630-360	38U	1800mm	600mm	1	Black Grey	RAL 7021
21630-362	42U	2000mm	600mm	1	Black Grey	RAL 7021
21630-364	47U	2200mm	600mm	1	Black Grey	RAL 7021
21630-361	38U	1800mm	800mm	1	Black Grey	RAL 7021
21630-363	42U	2000mm	800mm	1	Black Grey	RAL 7021

CatalogNumber	Rack Height	Height	Width	Package Quantity	Color	Color Code
21630-365	47U	2200mm	800mm	1	Black Grey	RAL 7021

Table 2/2

Catalog Number	Finish	Quick Ship
21630-360	Powder Coated	No
21630-362	Powder Coated	No
21630-364	Powder Coated	No
21630-361	Powder Coated	No
21630-363	Powder Coated	No
21630-365	Powder Coated	No

## ADDITIONAL PRODUCT DETAILS

The height of the rear panel is 400 mm less than the cabinet height to accomodate the connecting plate.

Please purchase the grounding kit separately.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**