

# 112 Loop Hanger with Flared Edges



## CERTIFICATIONS



## FEATURES

For steel and CPVC pipe

Flared edges help to protect plastic pipe

An integral fold-over washer (pipe sizes 2 1/2" to 8")

## SPECIFICATIONS

**Finish:** Electrogalvanized

**Material:** Steel

Table 1/2

| Catalog Number | Article Number | NB/DN | Outer Diameter (OD) | Rod Size (RS) | A       | B       |
|----------------|----------------|-------|---------------------|---------------|---------|---------|
| 1120050EG      |                | 15    | 21 mm               | 3/8"          | 70.7 mm | 29.2 mm |
| 1120075EG      |                | 20    | 27 mm               | 3/8"          | 76.4 mm | 32.2 mm |
| 1120100EG      |                | 25    | 34 mm               | 3/8"          | 83.7 mm | 36.2 mm |

| CatalogNumber | Article Number | NB/DN | Outer Diameter (OD) | Rod Size (RS) | A        | B        |
|---------------|----------------|-------|---------------------|---------------|----------|----------|
| 1120125EG     |                | 32    | 43 mm               | 3/8"          | 92.1 mm  | 40.2 mm  |
| 1120150EG     |                | 40    | 48 mm               | 3/8"          | 98.2 mm  | 43.2 mm  |
| 1120200EG     |                | 50    | 60 mm               | 3/8"          | 110.2 mm | 49.2 mm  |
| 1120250EG     |                | 65    | 76 mm               | 3/8"          | 138.2 mm | 70.2 mm  |
| 1120300EG     |                | 80    | 89 mm               | 3/8"          | 154.1 mm | 78.2 mm  |
| 1120400EG     |                | 100   | 114 mm              | 3/8"          | 193.8 mm | 105.2 mm |
| 112M0050EG    | 297860         | 15    | 21.3 mm             | M10           | 70.7 mm  | 29.2 mm  |
| 1120500EG     |                | 125   | 140 mm              | 1/2"          | 236.2 mm | 125.9 mm |
| 1120600EG     |                | 150   | 165 mm              | 1/2"          | 262.7 mm | 138.9 mm |
| 1120800EG     |                | 200   | 219 mm              | 1/2"          | 337.6 mm | 187.9 mm |
| 112B0500EG    |                | 125   | 141 mm              | 1/2"          | 236.2 mm | 125.9 mm |
| 112B0600EG    |                | 150   | 165 mm              | 1/2"          | 262.7 mm | 138.9 mm |
| 112B0800EG    |                | 200   | 219 mm              | 1/2"          | 337.6 mm | 187.9 mm |
| 112M0100EG    | 297880         | 25    | 26.9 mm             | M10           | 83.8 mm  | 36.2 mm  |
| 112M0125EG    | 297890         | 32    | 42.4 mm             | M10           | 92.1 mm  | 40.2 mm  |
| 112M0150EG    | 297900         | 40    | 48.3 mm             | M10           | 98.2 mm  | 43.2 mm  |
| 112M0200EG    | 297910         | 50    | 60.3 mm             | M10           | 110.2 mm | 49.2 mm  |
| 112M0075EG    | 297870         | 20    | 26.9 mm             | M10           | 76.4 mm  | 32.2 mm  |

| CatalogNumber | Article Number | NB/DN | Outer Diameter (OD) | Rod Size (RS) | A        | B        |
|---------------|----------------|-------|---------------------|---------------|----------|----------|
| 112M0250EG    | 297920         | 65    | 76.1 mm             | M10           | 138.2 mm | 70.2 mm  |
| 112M0300EG    | 297930         | 80    | 88.9 mm             | M10           | 154.1 mm | 78.2 mm  |
| 112M0400EG    | 297940         | 100   | 114.3 mm            | M10           | 193.8 mm | 105.2 mm |
| 112M0600EG    | 297960         | 150   | 165 mm              | M12           | 262.7 mm | 138.9 mm |
| 112M0500EG    | 297950         | 125   | 141 mm              | M12           | 236.2 mm | 125.9 mm |
| 112M0800EG    | 297970         | 200   | 219.1 mm            | M12           | 337.6 mm | 187.9 mm |


Table 2/2

| Catalog Number | Article Number | C       | Static Load | Certifications                               |
|----------------|----------------|---------|-------------|----------------------------------------------|
| 1120050EG      |                | 26.2 mm | 1334N       | UL, cUL                                      |
| 1120075EG      |                | 26.5 mm | 1334N       | UL, FM Approved, Pipe Hanger Components, cUL |
| 1120100EG      |                | 27.1 mm | 1334N       | UL, FM Approved, Pipe Hanger Components, cUL |
| 1120125EG      |                | 26.7 mm | 1334N       | UL, FM Approved, Pipe Hanger Components, cUL |
| 1120150EG      |                | 26.7 mm | 1334N       | UL, FM Approved, Pipe Hanger Components, cUL |
| 1120200EG      |                | 26.7 mm | 1334N       | UL, FM Approved, Pipe Hanger Components, cUL |
| 1120250EG      |                | 41.3 mm | 2340N       | UL, FM Approved, Pipe Hanger Components, cUL |
| 1120300EG      |                | 41.4 mm | 2340N       | UL, FM Approved, Pipe Hanger Components, cUL |
| 1120400EG      |                | 55.7 mm | 3780N       | UL, FM Approved, Pipe Hanger Components, cUL |

| Catalog Number | Article Number | C       | Static Load | Certifications                               |
|----------------|----------------|---------|-------------|----------------------------------------------|
| 112M0050EG     | 297860         | 26.2 mm | 1330N       | UL, cUL                                      |
| 1120500EG      |                | 65.4 mm | 3780N       | UL, FM Approved, Pipe Hanger Components, cUL |
| 1120600EG      |                | 64.9 mm | 3500N       | UL, FM Approved, Pipe Hanger Components, cUL |
| 1120800EG      |                | 88.5 mm | 6000N       | UL, FM Approved, Pipe Hanger Components, cUL |
| 112B0500EG     |                | 65.4 mm | 4440N       |                                              |
| 112B0600EG     |                | 64.9 mm | 4440N       |                                              |
| 112B0800EG     |                | 88.5 mm | 4440N       |                                              |
| 112M0100EG     | 297880         | 27.1 mm | 1330N       | UL, FM Approved, Pipe Hanger Components, cUL |
| 112M0125EG     | 297890         | 26.7 mm | 1330N       | UL, FM Approved, Pipe Hanger Components, cUL |
| 112M0150EG     | 297900         | 26.7 mm | 1330N       | UL, FM Approved, Pipe Hanger Components, cUL |
| 112M0200EG     | 297910         | 26.7 mm | 1330N       | UL, FM Approved, Pipe Hanger Components, cUL |
| 112M0075EG     | 297870         | 26.5 mm | 1330N       | UL, FM Approved, Pipe Hanger Components, cUL |
| 112M0250EG     | 297920         | 41.3 mm | 2340N       | UL, FM Approved, Pipe Hanger Components, cUL |
| 112M0300EG     | 297930         | 41.4 mm | 2340N       | UL, FM Approved, Pipe Hanger Components, cUL |
| 112M0400EG     | 297940         | 55.7 mm | 2890N       | UL, FM Approved, Pipe Hanger Components, cUL |

| Catalog Number | Article Number | C       | Static Load | Certifications                               |
|----------------|----------------|---------|-------------|----------------------------------------------|
| 112M0600EG     | 297960         | 64.9 mm | 4450N       | UL, FM Approved, Pipe Hanger Components, cUL |
| 112M0500EG     | 297950         | 65.4 mm | 2890N       | UL, FM Approved, Pipe Hanger Components, cUL |
| 112M0800EG     | 297970         | 88.5 mm | 6000N       | UL, FM Approved, Pipe Hanger Components, cUL |

### DIAGRAMS

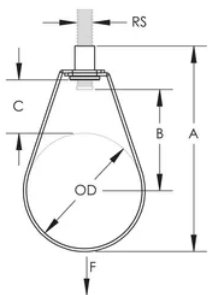

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221  
 Option 1 – Customer Care  
 Option 2 – Technical Support

#### Europe

Netherlands:  
 +31 800-0200135  
 France:  
 +33 800 901 793

#### Europe

Germany:  
 800 1890272  
 Other Countries:  
 +31 13 5835404

#### APAC

Shanghai:  
 + 86 21 2412 1618/19  
 Sydney:  
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

