

# Easy Universal Sway Brace, 1 1/2" Pipe, 40 DN

## CATALOG NUMBER

**CSBEZU0150EG**



## CERTIFICATIONS



## FEATURES

Use for both lateral and longitudinal sway brace applications

Unique slotted holes provide for easy slip-on installation eliminating loose hardware

Snap-off bolt head helps enable easy installation and inspection of seismic sway braces

Works with 1" through 2" brace pipes to reduce inventory

Meets NFPA®-13 requirements for seismic sway bracing

## PRODUCT ATTRIBUTES

Article Number: 404358

Material: Steel;Cast Iron

Finish: Electrogalvanized

Pipe Size: 1 1/2"

NB/DN: 40

A: 196.9 mm


B: 25.4 mm

Brace Pipe Size: 1" - 2"

Brace NB/DN: 25 - 50 mm

UL Loads (Listed for Sway Braces)			
Part Number	Lateral	Longitudinal	Brace Member
	KS D 3507/KS D 3562 Service Pipe	KS D 3507/KS D 3562 Service Pipe	
CSBEZU0200	5338 N	N/A	25A to 32A KS D 3562
CSBEZU0300	7117 N	3025 N	25A to 32A KS D 3562
CSBEZU0400	8896 N	4448 N	25A to 32A KS D 3562
CSBEZU0500	8896 N	4849 N	25A to 32A KS D 3562
CSBEZU0600	8896 N	4849 N	25A to 32A KS D 3562

DIAGRAMS

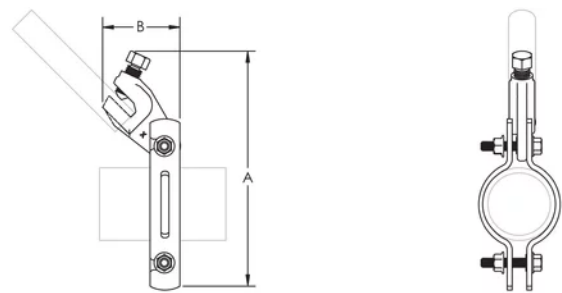

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

