

Hammer-On Flange Clip, Side Mount



CERTIFICATIONS



FEATURES

Provides an attachment for wire, S-hooks, chain, nVent CADDY Speed Link or other assemblies to flanges and profiles

Fits most beams

Installs with just a hammer

SPECIFICATIONS

Finish: nVent CADDY Armour


Material: Spring Steel

Table 1/1

Catalog Number	Article Number	Flange Thickness (FT)	Hole Size (HS)	Static Load	Certifications
2H4	170010	2 - 3 mm	7.1 mm	700N	ITB, UL, cUL
4H24	170020	3 - 8 mm	7.1 mm	900N	cUL, CE, 4H, EM, EBC, ITB, UL
4H58	170030	8 - 14 mm	7.1 mm	900N	CE, 4H, EM, EBC, ITB, UL, cUL

Catalog Number	Article Number	Flange Thickness (FT)	Hole Size (HS)	Static Load	Certifications
4H912	170040	14 - 20 mm	7.1 mm	900N	CE, 4H, EM, EBC, cUL, ITB, UL

DIAGRAMS

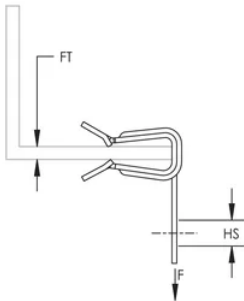

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

