

19" Front Panel

Data Solutions

Front panels made of Aluminum.



CERTIFICATIONS



FEATURES

Aluminum, 4 or 3 mm thick, with Anodized or Painted finish

SPECIFICATIONS

Rack Width:	95HP
Material:	Aluminum
Accessory Type:	Front panel
Product Type:	Front Panel

Table 1/3

Catalog Number	Rack Height	Depth (D)	Mounting	Finish	Front Finish	Package Quantity
30219-098	1U	3mm	Screw-on Front	Anodized	Anodized	1

CatalogNumber	Rack Height	Depth (D)	Mounting	Finish	Front Finish	Package Quantity
30118-948	1U	3mm	Screw-on Front	Powder Coated	Painted	1
30118-299	1U	3mm	Screw-on Front	Powder Coated	Painted	1
40304-074	1U	4mm	Screw-on Front	Anodized	Anodized	1
30219-101	2U	3mm	Screw-on Front	Anodized	Anodized	1
30118-301	2U	3mm	Screw-on Front	Powder Coated	Painted	1
30118-949	2U	3mm	Screw-on Front	Powder Coated	Painted	1
40304-075	2U	4mm	Screw-on Front	Anodized	Anodized	1
30219-104	3U	3mm	Screw-on Front	Anodized	Anodized	1
30118-302	3U	3mm	Screw-on Front	Powder Coated	Painted	1
30118-950	3U	3mm	Screw-on Front	Powder Coated	Painted	1
40304-076	3U	4mm	Screw-on Front	Anodized	Anodized	1
30219-107	4U	3mm	Screw-on Front	Anodized	Anodized	1
30118-303	4U	3mm	Screw-on Front	Powder Coated	Painted	1
30118-951	4U	3mm	Screw-on Front	Powder Coated	Painted	1
30219-110	5U	3mm	Screw-on Front	Powder Coated	Anodized	1
30118-304	5U	3mm	Screw-on Front	Powder Coated	Painted	1
30118-952	5U	3mm	Screw-on Front	Powder Coated	Painted	1
40304-077	4U	4mm	Screw-on Front	Anodized	Anodized	1

CatalogNumber	Rack Height	Depth (D)	Mounting	Finish	Front Finish	Package Quantity
30118-305	6U	3mm	Screw-on Front	Powder Coated	Painted	1
30118-308	9U	3mm	Screw-on Front	Powder Coated	Painted	1
30118-307	8U	3mm	Screw-on Front	Powder Coated	Painted	1
30118-306	7U	3mm	Screw-on Front	Powder Coated	Painted	1
30118-957	10U	3mm	Screw-on Front	Powder Coated	Painted	1
30118-956	9U	3mm	Screw-on Front	Powder Coated	Painted	1
30118-955	8U	3mm	Screw-on Front	Powder Coated	Painted	1
30118-954	7U	3mm	Screw-on Front	Powder Coated	Painted	1
30118-953	6U	3mm	Screw-on Front	Powder Coated	Painted	1
30118-309	10U	3mm	Screw-on Front	Powder Coated	Painted	1
40304-078	5U	4mm	Screw-on Front	Anodized	Anodized	1
30219-143	9U	3mm	Screw-on Front	Anodized	Anodized	1
30219-144	10U	3mm	Screw-on Front	Anodized	Anodized	1
30219-138	8U	3mm	Screw-on Front	Anodized	Anodized	1
40304-079	6U	4mm	Screw-on Front	Anodized	Anodized	1
30219-137	7U	3mm	Screw-on Front	Anodized	Anodized	1
40304-080	7U	4mm	Screw-on Front	Anodized	Anodized	1
40304-081	8U	4mm	Screw-on Front	Anodized	Anodized	1

CatalogNumber	Rack Height	Depth (D)	Mounting	Finish	Front Finish	Package Quantity
40304-082	9U	4mm	Screw-on Front	Anodized	Anodized	1
40304-083	10U	4mm	Screw-on Front	Anodized	Anodized	1
30219-113	6U	3mm	Screw-on Front	Anodized	Anodized	1

Table 2/3						
Catalog Number	Rear Finish	Treated Edges	Color Code	EMC Shielding	Height (H)	Type
30219-098	Anodized	No		No	43.6mm	19" Front Panel
30118-948	Painted		RAL 7021	No	43.6mm	19" Front Panel
30118-299	Painted		RAL 7035	No	43.6mm	19" Front Panel
40304-074	Anodized	Yes		No	43.6mm	19" Front Panel
30219-101	Anodized	No		No	88.1mm	19" Front Panel
30118-301	Painted		RAL 7035	No	88.1mm	19" Front Panel
30118-949	Painted		RAL 7021	No	88.1mm	19" Front Panel
40304-075	Anodized	Yes		No	88.1mm	19" Front Panel
30219-104	Anodized	No		No	132.5mm	19" Front Panel
30118-302	Painted		RAL 7035	No	132.5mm	19" Front Panel
30118-950	Painted		RAL 7021	No	132.5mm	19" Front Panel
40304-076	Anodized	Yes		No	132.5mm	19" Front Panel
30219-107	Anodized	No		No	177mm	19" Front Panel

CatalogNumber	Rear Finish	Treated Edges	Color Code	EMC Shielding	Height (H)	Type
30118-303	Painted		RAL 7035	No	177mm	19" Front Panel
30118-951	Painted		RAL 7021	No	177mm	19" Front Panel
30219-110	Anodized	No		No	221.4mm	19" Front Panel
30118-304	Painted		RAL 7035	No	221.4mm	19" Front Panel
30118-952	Painted		RAL 7021	No	221.4mm	19" Front Panel
40304-077	Anodized	Yes		No	177mm	19" Front Panel
30118-305	Painted		RAL 7035	No	265.9mm	19" Front Panel
30118-308	Painted		RAL 7035	No	399.2mm	19" Front Panel
30118-307	Painted		RAL 7035	No	354.8mm	19" Front Panel
30118-306	Painted		RAL 7035	No	310.3mm	19" Front Panel
30118-957	Painted		RAL 7021	No	443.7mm	19" Front Panel
30118-956	Painted		RAL 7021	No	399.2mm	19" Front Panel
30118-955	Painted		RAL 7021	No	354.8mm	19" Front Panel
30118-954	Painted		RAL 7021	No	310.3mm	19" Front Panel
30118-953	Painted		RAL 7021	No	265.9mm	19" Front Panel
30118-309	Painted		RAL 7035	No	443.7mm	19" Front Panel
40304-078	Anodized	Yes		No	221.4mm	19" Front Panel
30219-143	Anodized	No		No	399.2mm	19" Front Panel

CatalogNumber	Rear Finish	Treated Edges	Color Code	EMC Shielding	Height (H)	Type
30219-144	Anodized	No		No	443.7mm	19" Front Panel
30219-138	Anodized	No		No	354.8mm	19" Front Panel
40304-079	Anodized	Yes		No	265.9mm	19" Front Panel
30219-137	Anodized	No		No	310.3mm	19" Front Panel
40304-080	Anodized	Yes		No	310.3mm	19" Front Panel
40304-081	Anodized	Yes		No	354.8mm	19" Front Panel
40304-082	Anodized	Yes		No	399.2mm	19" Front Panel
40304-083	Anodized	Yes		No	443.7mm	19" Front Panel
30219-113	Anodized	No		No	265.9mm	19" Front Panel

Table 3/3

Catalog Number	Width (W)
30219-098	483mm
30118-948	483mm
30118-299	483mm
40304-074	483mm
30219-101	483mm
30118-301	483mm
30118-949	483mm
40304-075	483mm


Catalog Number	Width (W)
30219-104	483mm
30118-302	483mm
30118-950	483mm
40304-076	483mm
30219-107	483mm
30118-303	483mm
30118-951	483mm
30219-110	483mm
30118-304	483mm
30118-952	483mm
40304-077	483mm
30118-305	483mm
30118-308	483mm
30118-307	483mm
30118-306	483mm
30118-957	483mm
30118-956	483mm
30118-955	483mm

Catalog Number	Width (W)
30118-954	483mm
30118-953	483mm
30118-309	483mm
40304-078	483mm
30219-143	483mm
30219-144	483mm
30219-138	483mm
40304-079	483mm
30219-137	483mm
40304-080	483mm
40304-081	483mm
40304-082	483mm
40304-083	483mm
30219-113	483mm

ADDITIONAL PRODUCT DETAILS

Please order 19" assembly kit separately.

DIAGRAMS

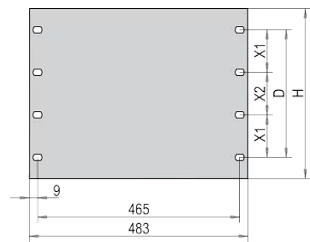

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE