

# C-EU Single Cable to Flange Clamp



## FEATURES

Supports single run of conduit

Attaches to beam flanges, angle iron, joists and other structural supports

## SPECIFICATIONS

**Finish:** Hot-Dip Galvanized

**Material:** Steel


Table 1/1

Catalog Number	Article Number	Outer Diameter (OD)	Flange Thickness (FT)	A	Torque (TQ)
C28EU	337340	24 - 28 mm	12 mm Max	58 mm Max	2 N·m
C32EU	337350	28 - 32 mm	12 mm Max	63 mm Max	2 N·m
C52EU	337400	48 - 52 mm	12 mm Max	90 mm Max	4 N·m

## ADDITIONAL PRODUCT DETAILS

Screw is electrogalvanized on clamps that have an outer diameter of 40 mm or less.

DIAGRAMS

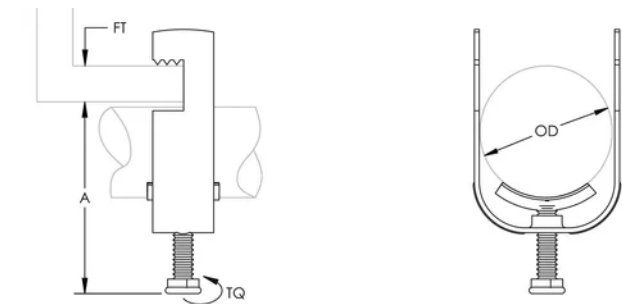

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

