

Hammer-On Flange Clip, Bottom Mount



CERTIFICATIONS



FEATURES

Can be used to support boxes, fixtures or other applications from beam flanges

Assorted attachment points provided to reduce inventory

Requires only a hammer to install

SPECIFICATIONS

Finish: nVent CADDY Armour

Material: Spring Steel


Table 1/2

Catalog Number	Article Number	Flange Thickness (FT)	Rod Size (RS)	Static Load 1 (F1)	Static Load 2 (F2)	Static Load 3 (F3)
EM24	170050	3 - 8 mm	6	450N	110N	330N
EM24R5	191026	3 - 8 mm	6	450N	110N	330N
EM58R5	191027	8 - 14 mm	6	450N	110N	330N

CatalogNumber	Article Number	Flange Thickness (FT)	Rod Size (RS)	Static Load 1 (F1)	Static Load 2 (F2)	Static Load 3 (F3)
EM912R5	191028	14 - 20 mm	6	450N	110N	330N
EM1318	170075	21 - 28 mm	6	450N	110N	330N

Table 2/2		
Catalog Number	Article Number	Certifications
EM24	170050	ITB, CE, 4H, EM, EBC
EM24R5	191026	CE, 4H, EM, EBC
EM58R5	191027	CE, 4H, EM, EBC
EM912R5	191028	CE, 4H, EM, EBC
EM1318	170075	cUL, UL

DIAGRAMS

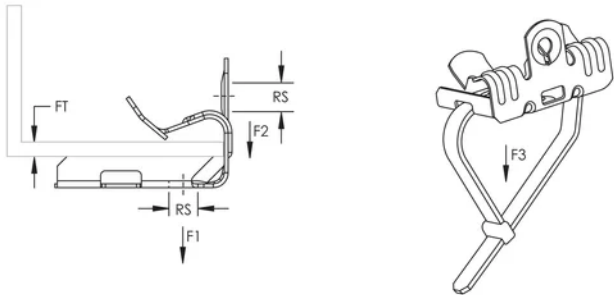

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

