

# nVent CADDY Superfix 243 M8/M10



## CERTIFICATIONS



## FEATURES

Includes easy closing mechanism

Combo head bolt works with slotted, hex, or Phillips drivers

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

## SPECIFICATIONS

<b>Color:</b>	Black
<b>Finish:</b>	Electrogalvanized
<b>Material:</b>	Steel;EPDM-SBR Rubber
<b>Temperature:</b>	-50 to 110 °C

Table 1/2

Catalog Number	Article Number	Outer Diameter (OD)	NB/DN	Rod Size (RS)	Width (W)	Thickness (T)
SXD014	400063	12 - 16 mm	8	M8, M10	20 mm	1.2 mm

CatalogNumber	Article Number	Outer Diameter (OD)	NB/DN	Rod Size (RS)	Width (W)	Thickness (T)
SXD019	400064	15 - 19 mm	10	M8, M10	20 mm	1.2 mm
SXD023	400065	20 - 23 mm	15	M8, M10	20 mm	1.2 mm
SXD028	400066	26 - 30 mm	20	M8, M10	20 mm	1.2 mm
SXD035	400067	31 - 36 mm	25	M8, M10	20 mm	1.2 mm
SXD043	400068	40 - 43 mm	32	M8, M10	20 mm	1.2 mm
SXD052	400070	48 - 53 mm	40	M8, M10	20 mm	1.2 mm
SXD058	589350	50 - 55 mm		M8, M10	20 mm	1.2 mm
SXD061	400071	60 - 64 mm	50	M8, M10	20 mm	1.2 mm
SXD080	400074	74 - 80 mm	65	M8, M10	20 mm	2 mm
SXD091	400075	87 - 92 mm	80	M8, M10	20 mm	2 mm
SXD114	400077	108 - 114 mm	100	M8, M10	23 mm	2 mm


Table 2/2				
Catalog Number	Article Number	Screw Diameter (Sc)	Screw Length (L)	Static Load
SXD014	400063	5	25mm	1000N
SXD019	400064	5	25mm	1000N
SXD023	400065	5	25mm	1000N
SXD028	400066	5	25mm	1000N
SXD035	400067	5	25mm	1000N
SXD043	400068	5	25mm	1000N

Catalog Number	Article Number	Screw Diameter (Sc)	Screw Length (L)	Static Load
SXD052	400070	5	25mm	1300N
SXD058	589350	5	30mm	1300N
SXD061	400071	5	30mm	1300N
SXD080	400074	6	35mm	1300N
SXD091	400075	6	35mm	1300N
SXD114	400077	6	35mm	2200N

### ADDITIONAL PRODUCT DETAILS

Lining is EPDM rubber.

### DIAGRAMS

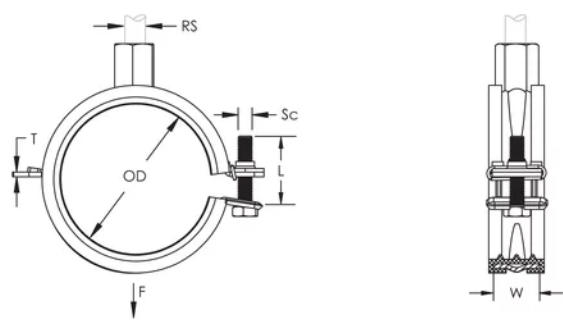

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

