

# PEMSA Wire Basket Tray C Bracket



## CERTIFICATIONS



## FEATURES

Easy to use, quick connect feature

Ideal for ceiling, wall and channel installations

Side load access for cable installation

IEC 61537 load rating and earthing compliant

## SPECIFICATIONS

**Finish:** Electrogalvanized


**Material:** Steel

Table 1/1

Catalog Number	Article Number	Length 1 (L1)	Length 2 (L2)	Width (W)	Height (H)	Static Load
WBT200CBRKT	820330	137 mm	265 mm	54 mm	190 mm	284N
WBT100CBRKT	820310	137 mm	165 mm	54 mm	190 mm	327N

CatalogNumber	Article Number	Length 1 (L1)	Length 2 (L2)	Width (W)	Height (H)	Static Load
WBT300CBRKT	820340	137 mm	365 mm	54 mm	190 mm	245N
WBT400CBRKT	820350	137 mm	465 mm	54 mm	190 mm	177N
WBT150CBRKT	820320	137 mm	200 mm	54 mm	190 mm	353N

### DIAGRAMS

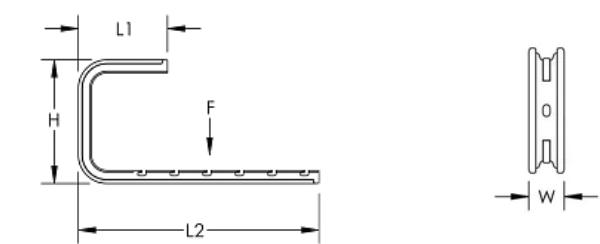

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221  
 Option 1 – Customer Care  
 Option 2 – Technical  
 Support

#### Europe

Netherlands:  
 +31 800-0200135  
 France:  
 +33 800 901 793

#### Europe

Germany:  
 800 1890272  
 Other Countries:  
 +31 13 5835404

#### APAC

Shanghai:  
 + 86 21 2412 1618/19  
 Sydney:  
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

