


# PESMT Medium Duty Pipe Slide, Two Connectors

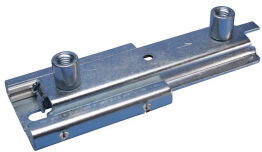

## FEATURES


For use with two pipe clamps

## SPECIFICATIONS

Catalog Number	PESMT
Article Number	580562
Material	Steel Polyamide
Finish	Electrogalvanized
Rod Size (RS)	M10 M12
Hole Size (HS)	12.5 mm
Height (H)	42 mm
Length (L)	165mm
Δ Length (ΔL)	140 mm
Width (W)	67 mm
A	123 mm
X	10.5 x 22 mm
Temperature	120 °C Max
Static Load 1 (F1)	2300N

Catalog Number	PESMT
Static Load 2 (F2)	2300N

### DIAGRAMS

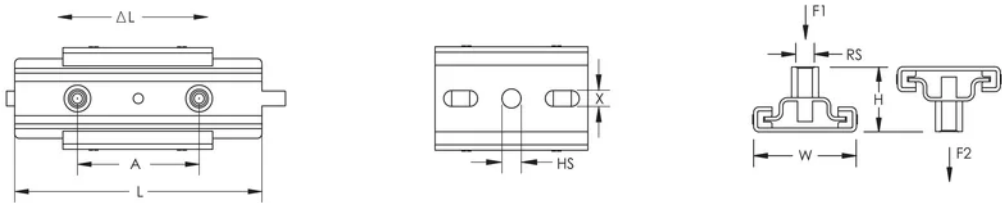

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

#### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

#### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

#### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

