

Female-Male Swivel Adaptor, Imperial Thread



CERTIFICATIONS



FEATURES

Allows air terminal to be positioned vertically when base is on a sloping roof

Male thread includes locknut for positioning

SPECIFICATIONS

Table 1/2


Catalog Number	Article Number	Material	Thread Size 1 (TS1)	Thread Size 2 (TS2)	Length 1 (L1)	Length 2 (L2)
LPS2855F5M		Stainless Steel 304 (EN 1.4301)	5/8" UNC	5/8" UNC	44.45 mm	69.85 mm
LPC2813F3M	701974	Copper	3/8" UNC	3/8" UNC	44.45 mm	69.85 mm
LPC2855F5M		Copper	5/8" UNC	5/8" UNC	44.45 mm	69.85 mm

Table 2/2

Catalog Number	Article Number	Unit Weight	Certifications
----------------	----------------	-------------	----------------

LPS2855F5M		0.22 kg	
LPC2813F3M	701974	0.23 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPC2855F5M		0.23 kg	E202878-Combined_CoC, E202878-Combined_CoC

DIAGRAMS

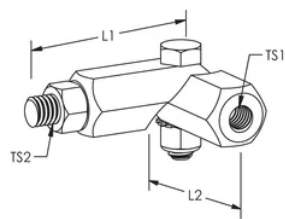

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE