


Insulated Tape Conductor

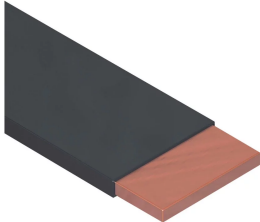

FEATURES

Provides a path to ground for lightning currents

Available in various colors to match building or design requirements

SPECIFICATIONS

Insulation Thickness: 1.0 - 1.5 mm

Material: Copper;Polyvinylchloride

Table 1/1

Catalog Number	Article Number	Conductor Width	Conductor Thickness	Length	Color	Unit Weight
CTBL25325	710595	25 mm	3 mm	25m	Black	0.77 kg
CTGY25325	710645	25 mm	3 mm	25m	Gray	0.77 kg
CTST25325	710655	25 mm	3 mm	25m	Stone	0.77 kg
CTWH25325	710666	25 mm	3 mm	25m	White	0.77 kg
CTYGN25325	710667	25 mm	3 mm	25m	Green, Yellow	0.77 kg

ADDITIONAL PRODUCT DETAILS

Unit weight is per meter (3.28').

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE