


# Universal Busbar Support with Neutral Circuit

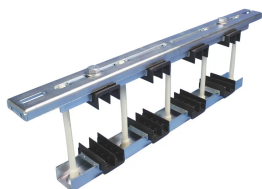

## CERTIFICATIONS



## FEATURES

Universal fixing system

Installs quickly and easily

Extremely robust construction

Adjustable arms for easy mounting

Halogen free insulators

## SPECIFICATIONS

|                                       |                                                                   |
|---------------------------------------|-------------------------------------------------------------------|
| <b>Max Working Voltage, IEC (Ui):</b> | 1000;1500                                                         |
| <b>Working Temperature:</b>           | -40 to 130 °C                                                     |
| <b>Material:</b>                      | Steel;Glass Fibre Reinforced Polyamide                            |
| <b>Complies With:</b>                 | IEC® 60439.1;IEC® 61439.1;IEC® 60695-2-11 (Glow Wire Test 960 °C) |
| <b>Flammability Rating:</b>           | UL® 94V-0                                                         |

Table 1/2


| Catalog Number | Article Number | Typical Application Current Rating | Busbars per Phase | Busbar Width | Busbar Thickness | Width (W) |
|----------------|----------------|------------------------------------|-------------------|--------------|------------------|-----------|
|----------------|----------------|------------------------------------|-------------------|--------------|------------------|-----------|

|           |        |        |       |             |       |              |
|-----------|--------|--------|-------|-------------|-------|--------------|
| UBS4-5TN  | 551010 | 3500 A | 1 - 4 | 30 - 125 mm | 5 mm  | 585 - 895 mm |
| UBS1-5TN  | 551000 | 1700 A | 1     | 30 - 125 mm | 5 mm  | 380 - 610 mm |
| UBS3-10TN | 551090 | 4500 A | 1 - 3 | 30 - 120 mm | 10 mm | 585 - 895 mm |
| UBS1-10TN | 551060 | 2250 A | 1     | 30 - 120 mm | 10 mm | 380 - 610 mm |
| UBS2-10TN | 551070 | 3600 A | 1 - 2 | 30 - 120 mm | 10 mm | 585 - 895 mm |

Table 2/2

| Catalog Number | Article Number | A            | B      | C      | D      |
|----------------|----------------|--------------|--------|--------|--------|
| UBS4-5TN       | 551010         | 560 - 865 mm | 281 mm | 480 mm | 110 mm |
| UBS1-5TN       | 551000         | 360 - 590 mm | 176 mm | 300 mm | 70 mm  |
| UBS3-10TN      | 551090         | 560 - 865 mm | 281 mm | 480 mm | 110 mm |
| UBS1-10TN      | 551060         | 360 - 590 mm | 176 mm | 300 mm | 70 mm  |
| UBS2-10TN      | 551070         | 560 - 865 mm | 281 mm | 480 mm | 110 mm |

## DIAGRAMS

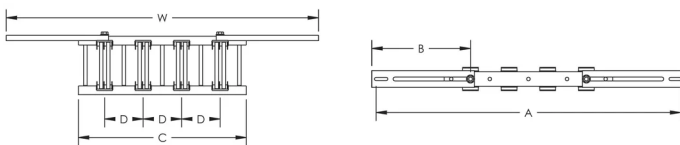

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**