


Socket with fuse CH, DIN rail mounting, plastic UL approved

CATALOG NUMBER

LPS10CH

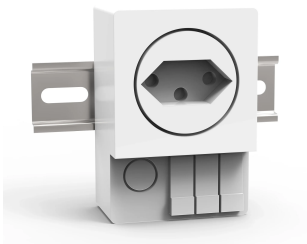

Easy to mount power sockets, to be mounted on a DIN rail, for use when external equipment needs to be plugged in.

INDUSTRY STANDARDS

cULus_UL listed

CE

GOST

FEATURES

Description: DIN rail mounted electrical socket. Pressure clamp connection for easy and quick wiring.

Dimensions: 92 mm x 62 mm x 48 mm.

Connection: 3 pressure clamps for stranded and rigid wire 0.5-2.5 mm². Integrated fuse 6,3A 5x20 mm.

Finish: Light grey.

Material: Plastic UL 94 V-0.

Pack quantity: 1 piece.

PRODUCT ATTRIBUTES

Height: 92mm

Width: 62mm

Depth: 48mm

Socket Type: Switzerland

Weight: 120kg

Material: Plastic

Finish: Smooth

Color: Light Gray

Color Code: RAL 7035

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE