


# Roof Exhaust Unit, REU

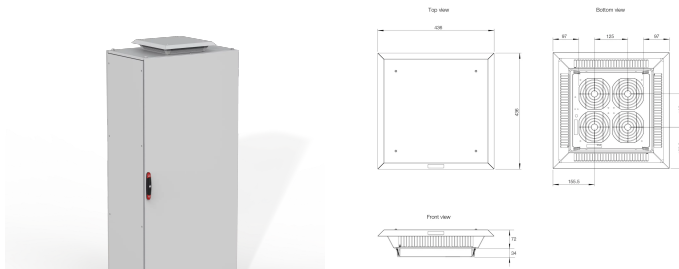

The roof exhaust unit, REU, with either a IP 33 or 54 protection degree, is easy to install thanks to its click-in feature. This is a good solution when there is limited space on the enclosure's door or side panels.

## INDUSTRY STANDARDS

UL 508A Component Recognized

CE

UKCA

EAC

## FEATURES

Description: Roof exhaust unit for mounting on the top of the enclosure, providing natural ventilation. The unit is easily installed with a quick fastening system. Filtration efficiency of >90% for the IP 54 unit (REU05R5).

Material: Painted mild steel, and injection-moulded thermoplastic (ABS-FR) self extinguishing, UL94V0.

Temperature range: -15 °C to +55 °C.

Protection: IP 33 No filtermat, IP54. Filtermat.

Finish: RAL 7035 structured powder coating.

Pack quantity: One roof exhaust unit.

Temperature range: -15 °C to +55 °C

SPECIFICATIONS

| Table 1/1      |        |       |       |            |               |            |
|----------------|--------|-------|-------|------------|---------------|------------|
| Catalog Number | Height | Width | Depth | Material   | Finish        | Color      |
| REU05R5        | 101mm  | 436mm | 436mm | Mild Steel | Powder Coated | Light Gray |
| REU03R5        | 101mm  | 436mm | 436mm | Mild Steel | Powder Coated | Light Gray |

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE