


Front Panel, Unshielded, Bottom Hinged

Power Utilities

Unshielded front panel bottom hinged.

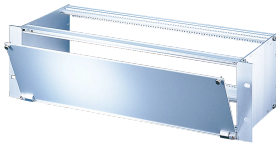

CERTIFICATIONS



FEATURES

Front panel can be unhinged at 135° (not RatiopacPRO) opening angle

Enables mounting on horizontal rails

SPECIFICATIONS

Table 1/3

Catalog Number	Rack Height	Rack Width	Package Quantity	Mounting	Front Finish	Rear Finish
20838-271	3 U	42 HP	1	Hinged, Bottom	Anodized	Conductive
20838-272	3 U	63 HP	1	Hinged, Bottom	Anodized	Conductive
20838-273	3 U	84 HP	1	Hinged, Bottom	Anodized	Conductive

CatalogNumber	Rack Height	Rack Width	Package Quantity	Mounting	Front Finish	Rear Finish
20838-274	6 U	42 HP	1	Hinged, Bottom	Anodized	Conductive
20838-275	6 U	63 HP	1	Hinged, Bottom	Anodized	Conductive
20838-276	6 U	84 HP	1	Hinged, Bottom	Anodized	Conductive
20838-277	4 U	42 HP	1	Hinged, Bottom	Anodized	Conductive
20838-278	4 U	63 HP	1	Hinged, Bottom	Anodized	Conductive
20838-279	4 U	84 HP	1	Hinged, Bottom	Anodized	Conductive
20838-280	3 U	28 HP	1	Hinged, Bottom	Anodized	Conductive

Table 2/3						
Catalog Number	Treated Edges	Complies With	EMC Shielding	Height	Material	Product Type
20838-271	No	IEC 60297-3-101, IEEE 1101.1/10	No	128.4 mm	Aluminum	Front Panel
20838-272	No	IEC 60297-3-101, IEEE 1101.1/10	No	128.4 mm	Aluminum	Front Panel
20838-273	No	IEC 60297-3-101, IEEE 1101.1/10	No	128.4 mm	Aluminum	Front Panel
20838-274	No	IEC 60297-3-101, IEEE 1101.1/10	No	261.8 mm	Aluminum	Front Panel
20838-275	No	IEC 60297-3-101, IEEE 1101.1/10	No	261.8 mm	Aluminum	Front Panel
20838-276	No	IEC 60297-3-101, IEEE 1101.1/10	No	261.8 mm	Aluminum	Front Panel
20838-277	No	IEC 60297-3-101, IEEE 1101.1/10	No	172.9 mm	Aluminum	Front Panel

CatalogNumber	Treated Edges	Complies With	EMC Shielding	Height	Material	Product Type
20838-278	No	IEC 60297-3-101, IEEE 1101.1/10	No	172.9 mm	Aluminum	Front Panel
20838-279	No	IEC 60297-3-101, IEEE 1101.1/10	No	172.9 mm	Aluminum	Front Panel
20838-280	No	IEC 60297-3-101, IEEE 1101.1/10	No	128.4 mm	Aluminum	Front Panel

Table 3/3

Catalog Number	Type	Width
20838-271	Front Panel without Handle	213 mm
20838-272	Front Panel without Handle	319.7 mm
20838-273	Front Panel without Handle	426.4 mm
20838-274	Front Panel without Handle	213 mm
20838-275	Front Panel without Handle	319.7 mm
20838-276	Front Panel without Handle	426.4 mm
20838-277	Front Panel without Handle	213 mm
20838-278	Front Panel without Handle	319.7 mm
20838-279	Front Panel without Handle	426.4 mm
20838-280	Front Panel without Handle	141.9 mm

ADDITIONAL PRODUCT DETAILS

Front panel can be removed in opened position (> 135°).

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper

installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE