


CableTek Horizontal Cable Manager

Data Solutions

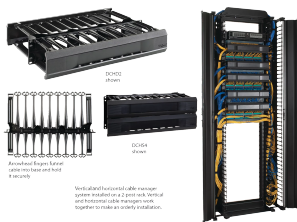

The CableTek Horizontal Cable Manager features heavy-duty endposts, arrowhead fingers and tool-less mounting to easily route Cat 5e, 6 and 6A cable horizontally in standard 19-in. cabinets or on 2- or 4-post open frame racks.

INDUSTRY STANDARDS

EIA 310-D

FEATURES

Snap-in mounting provision holds cable manager in place while mounting screws are installed

Robust arrowhead fingers are shaped to funnel cables into base and are made of black composite material

Robust rounded end posts support cable as it enters and leaves cable manager and maintains proper cable bend radius

Deep cable compartments allow maximum cable density

Rounded edges throughout protect cable jackets from damage

Pass-through holes on double-sided models protect cable while facilitating routing between front and back sides

Single- and double-sided units provide high cable capacity, including 5e, 6 and 6A cables

1 RU and 2 RU heights allow greater flexibility in optimizing rack capacity

Removable hinged cover opens top or bottom, snaps closed for assured cable protection and professional appearance

Double-sided model has covers on both front and back

Covers stay open during installation and maintenance procedures

Horizontal and vertical cable managers designed as a system for streamlined appearance and improved functionality

Combination head 10-32 and 12-24 screws included for mounting

Made of UL listed black composite material

SPECIFICATIONS

Table 1/3

Table 1/3						
Catalog Number	Article Number	Height	Width	Depth	Material	Finish

DCHS1	17241				ABS	Smooth Matte
DCHS2	17242	201mm	88mm	481mm	ABS	Smooth Matte
DCHD2	17243				ABS	Smooth Matte
DCHS4	26292				ABS	Smooth Matte

Table 2/3

Catalog Number	Article Number	Color	Color Code	Fill Rate, Back Cable, Cat 5e 0.22 in	Fill Rate, Back Cable, Cat 6 0.25 in	Fill Rate, Back Cable, Cat 6A 0.30 in
DCHS1	17241	Jet Black	RAL 9005			
DCHS2	17242	Jet Black	RAL 9005			
DCHD2	17243	Jet Black	RAL 9005	223	172	119
DCHS4	26292	Jet Black	RAL 9005			

Table 3/3

Catalog Number	Article Number	Rack Units	Fill Rate, Front Cable, Cat 5e 0.22 in	Fill Rate, Front Cable, Cat 6 0.25 in	Fill Rate, Front Cable, Cat 6A 0.30 in
DCHS1	17241	1U	66	57	35
DCHS2	17242	2U	208	161	112
DCHD2	17243	2U	208	161	112
DCHS4	26292	4U	416	322	224

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE