

nVent CADDY Cat CM U-Hook, 203 mm


Data Solutions

CATALOG NUMBER

CAT200CMLN



CERTIFICATIONS

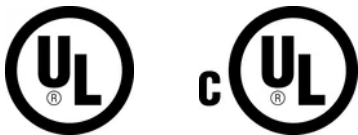

FEATURES

Provides optimal support for high-performance data cable, up to and including Cat 5e, Cat 6, Cat 6A, Cat 7 and fibre optic

System offers a convenient pathway for wires and cables

Specially designed U-Hooks have large-diameter, rounded support surfaces

U-Hooks can be mounted vertically along the same drop rod to create a tree configuration

Cantilever mounting allows U-Hooks to be mounted to walls and columns with brackets

Rounded edges help prevent over-bending and kinking of cables

Ideal for retrofit applications where cable runs need to be routed around existing building infrastructure

Compliant with NEC® and ANSI®/TIA structured cabling systems standards

PRODUCT ATTRIBUTES

Material: Steel

Finish: Electrogalvanized

Cable Capacity, Cat 5e: 450

Cable Capacity, Cat 6: 350

Cable Capacity, Cat 6A: 215


A: 203mm

Area: 533mm²

Hole Size (HS): 9.5mm

Static Load: 440N

DIAGRAMS

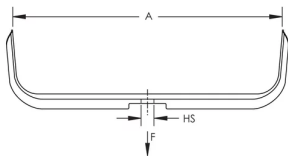

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE