

# Conductor Insulation Stripping Tool, 2 x 2



## FEATURES

Provides precision stripping with no conductor damage

Strips quickly, even in cold climates

Guarded cutting blades ensure safety

Bushings change easily with supplied hex wrench

## SPECIFICATIONS

**Length (L):** 146mm


**Material:** Aluminum;Steel

Table 1/1

Catalog Number	Bushing A	Bushing B
SBRT36100106	3/16" Bondstrand, 4/64" Insulation	#6 Sol, Concentric 8/64" Insulation
SBRT36100135	3/16" Bondstrand, 4/64" Insulation	#9 Sol, 10/64" Insulation
SBRT36100136	3/16" Bondstrand, 4/64" Insulation	3/16" Bondstrand, 6/64" Insulation
SBRT36100139	3/16" Bondstrand, 4/64" Insulation	#6 Sol, Concentric 11/64" Insulation
SBRT36100177	3/16" Bondstrand, 4/64" Insulation	#6 Sol, 12/64" Insulation

Catalog Number	Bushing A	Bushing B
SBRT36100138	3/16" Bondstrand, 6/64" Insulation	#6 Sol, Concentric 8/64" Insulation
SBRT36100140	3/16" Bondstrand, 6/64" Insulation	#6 Sol, Concentric 11/64" Insulation
SBRT36100142	#6 Sol, 1/64" Insulation	#6 Sol, Concentric 12/64" Insulation
SBRT36100148	7 Conductor, 6/64" Insulation	#9 Sol, 6/64" Insulation

## DIAGRAMS

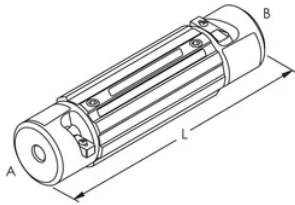

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE