

# Rail Profile Template



## FEATURES

Provides specific, safe and easy positioning of hole height on the rail profile

Universal rail profile templates can accommodate multiple rail profiles

Suitable for use with nVent ERICO SBMV2, SBMV4, SBME48VDC and SBME230VAC rail drill machines

Installs easily on rail drill machines

## SPECIFICATIONS

**Hole Size (HS):** 6.5 mm

**Diameter (Ø):** 54 mm

**Material:** Steel

Table 1/1


Catalog Number	Article Number	Template Type	Width (W)	Rail Type	Hole Height (HH)
RPT100LB	716204	Regular	82.5 mm	100 lb ARAB	66.8mm
RPT115LB	716203	Regular	82.5 mm	115 lb AREA	75.7mm
RPT132RE	716211	Regular	82.5 mm	132 lb RE	81.3mm
RPT136RE	716212	Regular	82.5 mm	136 lb RE, TR68	85.3mm
RPT141AB	716213	Regular	82.5 mm	141 lb AB	88.1mm

Catalog Number	Article Number	Template Type	Width (W)	Rail Type	Hole Height (HH)
RPT43KG625	715509	Regular	82.5 mm	43 kg	62.5mm
RPT50KG63	715513	Regular	82.5 mm	50 kg	63mm
RPT60KG738	715512	Regular	82.5 mm	60 kg	73.8mm
RPT70LBASCS	716215	Regular	82.5 mm	70 lb ASCS	52.1mm
RPT90LB655	716207	Regular	82.5 mm	90 lb ARA, TR45	66.5mm
RPT90LBARAA	716216	Regular	82.5 mm	90 lb ARAA	64.5mm
RPTAS41KG603	715543	Regular	82.5 mm	AS41	60.3mm
RPTAS4758		Regular	82.5 mm	AS47	58mm
RPTAS47619	715556	Regular	82.5 mm	AS47	61.9mm
RPTAS50KG67	715545	Regular	82.5 mm	AS50	67mm
RPTAS5364		Regular	82.5 mm	AS53	64mm
RPTAS53AS60NAX		Regular	82.5 mm	AS46, AS53	62.5mm
RPTAS6068		Regular	82.5 mm	AS60	68mm
RPTAS60KG745	715542	Regular	82.5 mm	AS60	74.5mm
RPTBH95RBS64	715367	Regular	82.5 mm	BH95RBS	64.69mm
RPTBHP42KG58	715544	Regular	82.5 mm	BHP42	58mm
RPTBS100A	715529	Regular	82.5 mm	BS100A	76.2mm
RPTBS80A	715528	Regular	82.5 mm	BS80A	65.53mm

Catalog Number	Article Number	Template Type	Width (W)	Rail Type	Hole Height (HH)
RPTBS90A56	715559	Regular	82.5 mm	BS90A	56mm
RPTEB50T675	715364	Regular	82.5 mm	50 kg	67.5mm
RPTIR52KG69	715557	Regular	82.5 mm	52 kg	69mm
RPTK4063	716206	Regular	82.5 mm	K40	63mm
RPTNP4AM805	715571	Regular	82.5 mm	NP4AM	80.5mm
RPTNP4AM865	715572	Regular	82.5 mm	NP4AM	86.5mm
RPTNP4AM893	715573	Regular	82.5 mm	NP4AM	93mm
RPTR65785	715560	Regular	82.5 mm	R65	78.5mm
RPTRI6087	715577	Regular	82.5 mm	RI60	87mm
RPTRP42		Regular	82.5 mm	RP42	60.5mm
RPTRP54		Regular	82.5 mm	RP54	70mm
RPTS41595	715540	Regular	82.5 mm	S41	59.5mm
RPTS49475	715578	Regular	82.5 mm	S49	47.5mm
RPTUIC5472		Regular	82.5 mm	UIC	72mm
RPTUIC6074	715536	Regular	82.5 mm	UIC60	74mm
RPTUIC60763		Regular	82.5 mm	UIC60	76.3mm
RPTUNI	715365	Universal	95 mm	S49, S54, UIC60	62.5mm
RPTUNIVABC	716201	Universal	95 mm	BS90A, UIC54, UIC60	70mm

Catalog Number	Article Number	Template Type	Width (W)	Rail Type	Hole Height (HH)
RPTUNIVEFG	716202	Universal	95 mm	AS50, AS60, BHP42	74.5mm
RPTVRC50CN	715133	Regular	82.5 mm	VRC50	68.5mm
RPTVRC60CN	715558	Regular	82.5 mm	VRC60	79mm

## DIAGRAMS

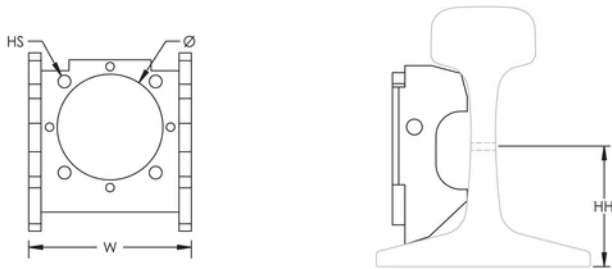

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**