

# CABS Aluminum Profile, UL®



## CERTIFICATIONS



## FEATURES

For use with CABS module kits, UL

Available in multiple lengths to accommodate various widths and depths of enclosures

Factory punched holes for quick assembly

Evenly spaced holes provide consistent and accurate spacing

Improve bending resistance by interlocking or stacking two profiles

Time-savings and lower total install costs compared to traditional methods

Engineered and standardized design

RoHS compliant

## SPECIFICATIONS

**Material:** Aluminum

**Finish:** Anodized

Table 1/2


| Catalog Number | Article Number | Length (L) | Height (H) | Width (W) | Hole Size (HS) | A |
|----------------|----------------|------------|------------|-----------|----------------|---|
|----------------|----------------|------------|------------|-----------|----------------|---|

|          |        |          |         |         |         |       |
|----------|--------|----------|---------|---------|---------|-------|
| CABSAL18 | 549512 | 457.2mm  | 29.2 mm | 45.7 mm | 11.9 mm | 19 mm |
| CABSAL24 | 549513 | 609.6mm  | 29.2 mm | 45.7 mm | 11.9 mm | 19 mm |
| CABSAL30 | 549514 | 762mm    | 29.2 mm | 45.7 mm | 11.9 mm | 19 mm |
| CABSAL36 | 549515 | 914.4mm  | 29.2 mm | 45.7 mm | 11.9 mm | 19 mm |
| CABSAL48 | 549516 | 1219.2mm | 29.2 mm | 45.7 mm | 11.9 mm | 19 mm |
| CABSAL54 | 549517 | 1371.6mm | 29.2 mm | 45.7 mm | 11.9 mm | 19 mm |

Table 2/2

| Catalog Number | Article Number | Unit Weight |
|----------------|----------------|-------------|
| CABSAL18       | 549512         | 0.69 kg     |
| CABSAL24       | 549513         | 0.92 kg     |
| CABSAL30       | 549514         | 1.15 kg     |
| CABSAL36       | 549515         | 1.38 kg     |
| CABSAL48       | 549516         | 1.84 kg     |
| CABSAL54       | 549517         | 2.07 kg     |

## DIAGRAMS

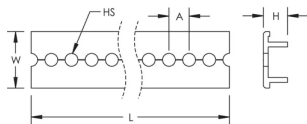

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**