

# Hydraulic Busbar Cutter



## CERTIFICATIONS



## FEATURES

Works with copper or aluminium busbar

Produces a flat and clean cut edge

Clear plastic shields allow for visual inspection of cutting position

Strong mechanical assembly

Replacement blade available

Easy access for blade maintenance

RoHS compliant

## SPECIFICATIONS

Table 1/2

| Catalog Number | Article Number | Busbar Width | Busbar Thickness | Depth (D) | Height (H) | Width (W) |
|----------------|----------------|--------------|------------------|-----------|------------|-----------|
| HYDR-BB-CUT    | 545690         | 125 mm Max   | 12.7 mm Max      | 240mm     | 395 mm     | 286 mm    |

Table 2/2


| Catalog Number | Article Number | Unit Weight |
|----------------|----------------|-------------|
|----------------|----------------|-------------|

|             |        |       |
|-------------|--------|-------|
| HYDR-BB-CUT | 545690 | 41 kg |
|-------------|--------|-------|

## ADDITIONAL PRODUCT DETAILS

Do not use to cut nVent ERIFLEX Flexibar.

## DIAGRAMS

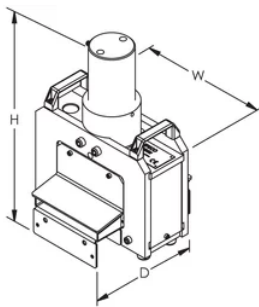

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**