

nVent ERIFLEX Flexbus Transformer Cover IP2X for 1 Conductor per Phase



CERTIFICATIONS



FEATURES

Input/output for neutral/ground conductor

Resistance to solvent and hydrocarbon splashes

Installs quickly and easily

UV resistance

SPECIFICATIONS


Table 1/2

Catalog Number	Article Number	Material	Working Temperature	Length (L)	Width (W)	Depth (D)
FLEXCOVIP2X0 NE	508160	Polyvinylchloride	-40 to 140 °C	465mm	182 mm	126mm

Table 2/2

Catalog Number	Article Number	Unit Weight
----------------	----------------	-------------

DIAGRAMS

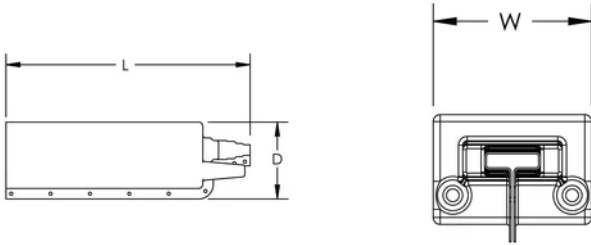

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE