


Frame-Reducing Brackets for Frames or Grid Straps

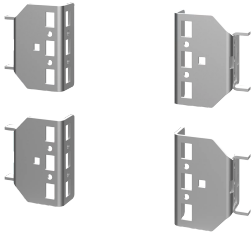

Frame-Reducing Brackets mount directly to 700- or 800-mm wide ProLine frames or to grid straps. Converts wider frames to 600-mm wide, allowing 19-in. rack angles to fit, or to 700-mm wide, allowing 23-in. rack angles to fit. Can be used to left- or right-justify the rack-mounted equipment. Furnished in sets of four. Mounting hardware is included.

FEATURES

Furnished in set of four; mounting hardware included

14 gauge (1.75 mm) conductive steel

Mount directly to 700- or 800-mm wide ProLine frames or to grid straps. Converts wider frames to 600-mm wide, allowing 19-in. rack angles to fit, or to 700-mm wide, allowing 23-in. rack angles to fit.

Can also be used to left- or right-justify the rack-mounted equipment through the use of a single bracket or combination of brackets.

SPECIFICATIONS

Thickness: 1.9mm

Finish: Plated

Table 1/1

Catalog Number	Article Number	Material	Reduces Frame Width	Converts Frame Width	Quick Ship
PRB50	77280	Mild Steel	50mm	From 700 mm to 600 mm, From 800 mm to 700 mm	No
PRB100	79560	Mild Steel	100mm	From 800 mm to 600 mm, From 800 mm to 700 mm, From 700 mm to 600 mm	No
PRB200	79570	Mild Steel	200mm	From 1000 mm to 600 mm, From 1000 mm to 800 mm, From 800 mm to 600 mm	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE