


Inline Landscape Panels

Inline Landscape Panels are available painted white or a conductive finish.

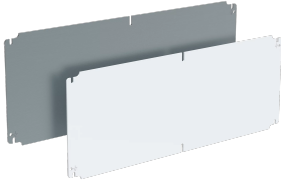

FEATURES

Include a labeled ground hole sized for an M6 screw

Panels mount on studs provided in the enclosure or to optional DIN mounting brackets

SPECIFICATIONS

Material: Mild Steel

Table 1/1

Catalog Number	Article Number	Height	Width	Finish	Color	Thickness
LP2331	11066	211mm	291mm	Powder Coated	White	2.66mm
LP2331G	15157	211mm	291mm	Galvanized		2.66mm
LP2346	11067	211mm	440mm	Powder Coated	White	2.66mm
LP2346G	15158	211mm	440mm	Galvanized		2.66mm
LP2360	11068	211mm	580mm	Powder Coated	White	2.66mm
LP2360G	15161	211mm	580mm	Galvanized		2.66mm
LP2377	11071	211mm	751mm	Powder Coated	White	2.66mm
LP2377G	15162	211mm	751mm	Galvanized		2.66mm
LP2393	11072	211mm	906mm	Powder Coated	White	2.66mm
LP2393G	15163	211mm	906mm	Galvanized		2.66mm

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE