

# T-Series Vertical Transition Filler Material Kit



T-Series vertical filler material kits contain the following: Filler material, two vertical packings, pouring basin ceramic guide tube and pouring basin crucible ceramic and disk. All filler material kits contain one-time use components that are sized to a specific sleeve, pouring basin and pouring basin crucible combination. Ordering filler material kits simplifies ordering, reduces order errors and helps ensure proper sizing of components.

## FEATURES

Simplifies ordering

Used to splice different diameter bars

All components are for one-time use

## SPECIFICATIONS

Table 1/1

Catalog Number	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada
RBT911101B	36 mm, 28 mm	#11, #9	35M, 30M
RBT910101B	32 mm, 28 mm	#10, #9	
RBT1114101B	43 mm, 36 mm	#14, #11	45M, 35M
RBT1118101B	57 mm, 36 mm	#18, #11	55M, 35M
RBT1011101B	36 mm, 32 mm	#11, #10	
RBT1418101B	57 mm, 43 mm	#18, #14	55M, 45M

ADDITIONAL PRODUCT DETAILS


Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System instruction manual.

Filler material kits are a component in splice kits. Care should be taken to avoid duplication of orders.

Components can also be purchased separately: (1) Filler Material, (2) Vertical Top Packing, (3) Vertical Bottom Packing, (4) Pouring Basin Ceramic Guide Tube, and (5) Crucible Ceramic and Disk.

Filler Material Kit Components				
Filler Material Kit	Filler Material	Packing (2 Required)	Pouring Basin Ceramic Insert and Disk	Pouring Basin Ceramic Guide Tube
RBT910101B	RBF105	RBS354712 RBS35475.5	RBS5037	RBS5038
RBT911101B	RBF125	RBS354714 RBS35476	RBS5037	RBS5038
RBT1011101B	RBF125	RBS354712 RBS35476	RBS5037	RBS5038
RBT1114101B	RBF125	RBS354715 RBS35476	RBS5037	RBS5039
RBT1118101B	RBF240	RBS354712 RBS354720	RBS5037	RBS5039
RBT1418101B	RBF195	RBS354720 RBS35477	RBS5037	RBS5039

DIAGRAMS

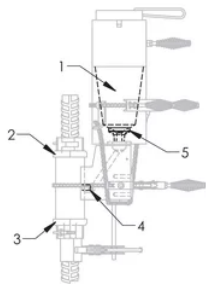

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**