


# Mounting Plate for 19" Case and Subrack

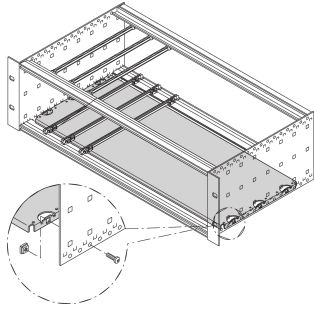

Mounting plate for heavy components or proprietary electronic assemblies. Suitable for RatiopacPRO/-AIR, CompacPRO and EuropacPRO.

Guide rails Type 4,4" and type strengthened cannot be used in combination with a mounting plate. Top / bottom cover which will be inserted into the groove of the light (type L) horizontal rails cannot be used in combination with a mounting plate.

## CERTIFICATIONS



## FEATURES

For assembly of heavy components

Mounting plate, full width: The mounting plate is as wide as the subrack/system case and is fixed to the side panels

Mounting plate, partial width: The partial width mounting plate fixed to the side panel by means of an assembly strip

The chassis plate can't be combined with EMC top- / bottom covers

## SPECIFICATIONS

|                      |                |
|----------------------|----------------|
| <b>Material:</b>     | Aluminum       |
| <b>Product Type:</b> | Mounting Plate |
| <b>Works With:</b>   | Subracks       |

Table 1/2

| Catalog Number | Rack Width | Package Quantity | Depth   | Product Family                     | Width    | Certifications |
|----------------|------------|------------------|---------|------------------------------------|----------|----------------|
| 34562-745      | 28HP       | 1                | 112.5mm | EuropacPRO, RatiopacPRO, CompacPRO | 146.88mm | RoHS           |

| CatalogNumber | Rack Width | Package Quantity | Depth   | Product Family                                | Width    | Certifications |
|---------------|------------|------------------|---------|-----------------------------------------------|----------|----------------|
| 34562-749     | 28HP       | 1                | 172.5mm | EuropacPRO, RatiopacPRO, CompacPRO            | 146.88mm | RoHS           |
| 34562-746     | 42HP       | 1                | 112.5mm | EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO | 217.99mm | RoHS           |
| 34562-753     | 28HP       | 1                | 232.5mm | EuropacPRO, RatiopacPRO, CompacPRO            | 146.88mm | RoHS           |
| 34562-757     | 28HP       | 1                | 292.2mm | EuropacPRO, RatiopacPRO, CompacPRO            | 146.88mm | RoHS           |
| 34562-747     | 63HP       | 1                | 112.5mm | EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO | 324.67mm | RoHS           |
| 34562-750     | 42HP       | 1                | 172.5mm | EuropacPRO, CompacPRO, RatiopacPRO, PropacPRO | 217.99mm | RoHS           |
| 34562-748     | 84HP       | 1                | 112.5mm | EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO | 324.67mm | RoHS           |
| 34562-754     | 42HP       | 1                | 232.5mm | EuropacPRO, RatiopacPRO, CompacPRO            | 217.99mm | RoHS           |
| 34562-751     | 63HP       | 1                | 172.5mm | EuropacPRO, RatiopacPRO, CompacPRO, PropacPRO | 324.67mm | RoHS           |
| 34562-758     | 42HP       | 1                | 292.2mm | EuropacPRO, RatiopacPRO, CompacPRO            | 217.99mm | RoHS           |
| 34562-752     | 84HP       | 1                | 172.5mm | EuropacPRO, CompacPRO, RatiopacPRO, PropacPRO | 431.35mm | RoHS           |
| 34562-755     | 63HP       | 1                | 232.5mm | EuropacPRO, RatiopacPRO, CompacPRO            | 324.67mm | RoHS           |
| 34562-759     | 63HP       | 1                | 292.2mm | EuropacPRO, RatiopacPRO, CompacPRO            | 324.67mm | RoHS           |

| CatalogNumber | Rack Width | Package Quantity | Depth   | Product Family                                | Width    | Certifications |
|---------------|------------|------------------|---------|-----------------------------------------------|----------|----------------|
| 34562-756     | 84HP       | 1                | 232.5mm | EuropacPRO, RatiopacPRO, CompacPRO            | 431.35mm | RoHS           |
| 34562-760     | 84HP       | 1                | 292.5mm | EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO | 431.35mm | RoHS           |
| 34562-870     | 84HP       | 1                | 352.5mm | EuropacPRO                                    | 431.35mm |                |
| 34562-871     | 84HP       | 1                | 412.5mm | EuropacPRO                                    | 431.35mm |                |

Table 2/2

| Catalog Number | Quick Ship |
|----------------|------------|
| 34562-745      | No         |
| 34562-749      | No         |
| 34562-746      | No         |
| 34562-753      | No         |
| 34562-757      | No         |
| 34562-747      | No         |
| 34562-750      | No         |
| 34562-748      | No         |
| 34562-754      | No         |
| 34562-751      | No         |
| 34562-758      | No         |
| 34562-752      | No         |

| Catalog Number | Quick Ship |
|----------------|------------|
| 34562-755      | No         |
| 34562-759      | No         |
| 34562-756      | No         |
| 34562-760      | No         |
| 34562-870      | No         |
| 34562-871      | No         |

## ADDITIONAL PRODUCT DETAILS

Please order assembly kit for mounting plate separately.

Other versions on request.

Fixing strips required for partial width, please order separately.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**