


# Static Handle Plastic in Trapezoid Form, Grey

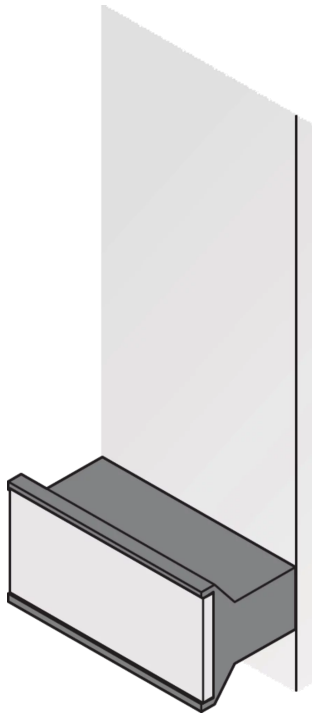

The static plastic handle, trapezoid form in grey color can be mounted to a front panel for extraction of the PCB.

## CERTIFICATIONS



## FEATURES

With separate identification plate, Al 1.5 mm

Handle, PC, UL 94 V-0

## SPECIFICATIONS

|                      |                     |
|----------------------|---------------------|
| <b>Works With:</b>   | Front Panels        |
| <b>Product Type:</b> | Handle              |
| <b>Material:</b>     | Polyphenylene Ether |
| <b>Type:</b>         | Static              |

Table 1/2

| Catalog Number | Rack Width | Package Quantity | Handle Type       | Flammability Rating | Color      | Color Code |
|----------------|------------|------------------|-------------------|---------------------|------------|------------|
| 20808-062      | 8HP        | 1                | Trapezoid, Static | UL® 94V-0           | Light Grey | RAL 7035   |
| 20808-004      | 10HP       | 1                | Trapezoid, Static | UL® 94V-0           | Light Grey | RAL 7035   |
| 20808-067      | 28HP       | 1                | Trapezoid, Static | UL® 94V-0           | Light Grey | RAL 7035   |
| 20808-009      | 40HP       | 1                | Trapezoid, Static | UL® 94V-0           | Grey       |            |
| 20808-068      | 42HP       | 1                | Trapezoid, Static | UL® 94V-0           | Light Grey | RAL 7035   |
| 20808-012      | 61HP       | 1                | Trapezoid, Static | UL® 94V-0           | Grey       |            |
| 20808-003      | 5HP        | 1                | Trapezoid, Static | UL® 94V-0           | Light Grey | RAL 7035   |
| 20808-060      | 6HP        | 1                | Trapezoid, Static | UL® 94V-0           | Light Grey | RAL 7035   |
| 20808-061      | 7HP        | 1                | Trapezoid, Static | UL® 94V-0           | Light Grey | RAL 7035   |
| 20808-063      | 9HP        | 1                | Trapezoid, Static | UL® 94V-0           | Grey       |            |
| 20808-064      | 12HP       | 1                | Trapezoid, Static | UL® 94V-0           | Light Grey | RAL 7035   |
| 20808-065      | 14HP       | 1                | Trapezoid, Static | UL® 94V-0           | Light Grey | RAL 7035   |
| 20808-066      | 21HP       | 1                | Trapezoid, Static | UL® 94V-0           | Light Grey | RAL 7035   |
| 20809-294      | 3HP        | 1                | Trapezoid, Static | UL® 94V-0           | Light Grey | RAL 7035   |
| 20809-295      | 4HP        | 1                | Trapezoid, Static | UL® 94V-0           | Light Grey | RAL 7035   |

Table 2/2

| Catalog Number | Complies With                             | Depth (D) | Height (H) | Width (W) | Quick Ship |
|----------------|-------------------------------------------|-----------|------------|-----------|------------|
| 20808-062      | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | 14mm      | 15.4mm     | 39.2mm    | No         |

| Catalog Number | Complies With                             | Depth (D) | Height (H) | Width (W) | Quick Ship |
|----------------|-------------------------------------------|-----------|------------|-----------|------------|
| 20808-004      | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | 14mm      | 15.4mm     | 49.4mm    | No         |
| 20808-067      | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | 14mm      | 15.4mm     | 140.8mm   | No         |
| 20808-009      | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 |           |            | 201.8mm   | No         |
| 20808-068      | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | 14mm      | 15.4mm     | 212mm     | No         |
| 20808-012      | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 |           |            | 308.5mm   | No         |
| 20808-003      | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | 14mm      | 15.4mm     | 24mm      | No         |
| 20808-060      | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | 14mm      | 15.4mm     | 29mm      | No         |
| 20808-061      | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | 14mm      | 15.4mm     | 34.1mm    | No         |
| 20808-063      | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 |           |            | 44.3mm    | No         |
| 20808-064      | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | 14mm      | 15.4mm     | 59.6mm    | No         |
| 20808-065      | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | 14mm      | 15.4mm     | 69.7mm    | No         |
| 20808-066      | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | 14mm      | 15.4mm     | 105.2mm   | No         |
| 20809-294      | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | 16.3mm    | 15.4mm     | 13.8mm    | No         |
| 20809-295      | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | 16.3mm    | 15.4mm     | 18.9mm    | No         |

## ADDITIONAL PRODUCT DETAILS

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

Cannot be used together with fixing clip (21101-239).

## DIAGRAMS



## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**