

Tip Receptor Mount

Power Utilities



FEATURES

Improved performance at tip of blade

Performance tested beyond IEC® 61400-24

Superior receptor product life performance


Less than 12 °C (54 °F) temperature rise after strike of 225 kA

SPECIFICATIONS

Table 1/1

Catalog Number	Height (H)	Width (W)	A
WT2TC1MV05.5	40 mm	106 mm	130 mm

DIAGRAMS

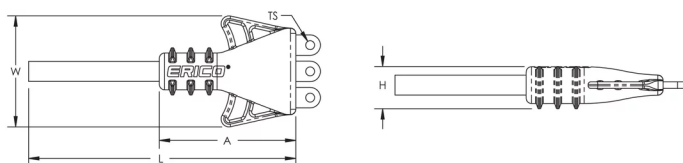

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE