

VKR Trapezoidal Deck Hanger



FEATURES

Supports threaded rod

SPECIFICATIONS

Finish: nVent CADDY Armour

Material: Spring Steel

Table 1/2

Catalog Number	Article Number	Rod Size (RS)	Flange Thickness (FT)	Hole Size (HS)	Diameter (Ø)	Static Load 1 (F1)
M8VKR	160650	8	0.8 - 3 mm	7 mm	7 mm	450N
M10VKR	160660	10	0.8 - 3 mm	7 mm	7 mm	450N
M6VKR	160640	6	0.8 - 3 mm	7 mm	7 mm	450N

Table 2/2


Catalog Number	Article Number	Static Load 2 (F2)
M8VKR	160650	900N
M10VKR	160660	900N

Catalog Number	Article Number	Static Load 2 (F2)
M6VKR	160640	600N

ADDITIONAL PRODUCT DETAILS

Static Load 1 represents 0.8 - 2.0 mm flange thickness. Static Load 2 represents 2.0 - 3.0 mm flange thickness.

DIAGRAMS

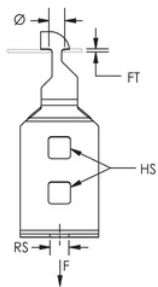

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

