


# PEMSA Wire Basket Tray Cable Outlet

## Data Solutions

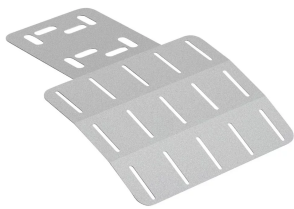

### CERTIFICATIONS



### FEATURES

Easy to install

Allows for easy exit angle adjustment (from 0 to 90 degrees)

### SPECIFICATIONS

**Material:** Steel


Table 1/2

Catalog Number	Article Number	Color	Finish	Length (L)	Width 1 (W1)	Width 2 (W2)
WBTCBLOUTBA	820801	Black		216mm	85mm	150mm
WBTCBLOUT	820800		Pregalvanized	216mm	85mm	150mm

Table 2/2

Catalog Number	Article Number	Thickness (T)	Hole Size 1 (HS1)	Hole Size 2 (HS2)	Certifications
WBTCBLOUTBA	820801	1.5mm	7 – 20mm	3 – 30mm	
WBTCBLOUT	820800	1.5mm	7 – 20mm	3 – 30mm	CE, CADDY EU WBT CBL

## DIAGRAMS

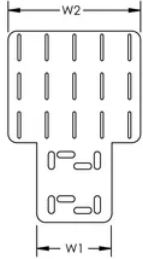

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**