

# Ground Rod Clamp, Rod to Conductor, Stainless Steel



## CERTIFICATIONS



## FEATURES

Unique stamped body design will not crack from excessive torque

Provides a greater surface area contact to allow improved performance of the connector

Compatible with copper, copper bonded, galvanized, stainless steel, rebar and plain steel ground rods and electrodes

## SPECIFICATIONS


Table 1/2

Catalog Number	Article Number	Material	Torque (TQ)	Ground Rod Diameter, Nominal	Ground Rod Diameter, Actual (Ø)	Conductor Size
SP58	158185	Stainless Steel 304 (EN 1.4301)	16.90 - 33.9 N·m	1/2" - 5/8"	12.7 - 15.9 mm	#10 Stranded - #2 Stranded, 6 mm² Stranded - 25 mm² Stranded

Table 2/2

Catalog Number	Article Number	Wrench Size
SP58	158185	1/2"

## DIAGRAMS

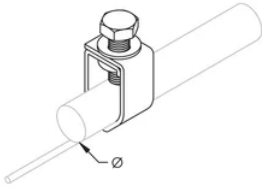

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**