


Small Polycarbonate Terminal Box, DPCP

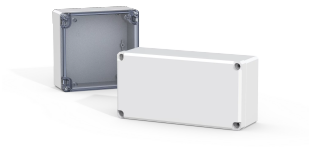

The polycarbonate terminal box range, DPCP, with a IP 66, 67 protection degree, is available off the shelf in many different sizes. The DPCP range is well suited for indoor and outdoor environments, even in locations where there is direct sunlight, thanks to the resistance to UV radiation. Water and dust are prevented from entering the terminal box, thus eliminating the risk for component failure, and with that, unnecessary downtime.

INDUSTRY STANDARDS

CE
UKCA
GOST
IP

FEATURES

Description: Polycarbonate box, halogen-free, suitable for outdoor use. High UV radiation resistance. Self-extinguishing.

Material: Polycarbonate.

Gasket: Polyurethane gasket integrated in the box cover.

Temperature resistance: -40 °C to +80 °C.

Flammability: UL746C 5V.

Protection: IP 66, 67 | IK 08 (-25 °C ... +35 °C).

Finish: RAL 7035.

Approvals: CE, GOST. For cULus_UL Listed approvals, please contact our sales department.

Delivery: Body, cover, cover screws manufactured from stainless steel, mounting screws and cover plugs made of polyamide.

Flammability: UL746C 5V

Protection: IP 66, 67 | IK 08 (-25 °C ... +35 °C)

Delivery: Body, cover, cover screws manufactured from stainless steel, mounting screws and cover plugs made of polyamide


SPECIFICATIONS

Color: Light Gray
Material: Polycarbonate
Color Code: RAL 7035
Finish: Smooth

Table 1/1

| Catalog Number | Height (H) | Width (W) | Depth (D) | Max Mounting Depth | Weight | Quick Ship |
|----------------|------------|-----------|-----------|--------------------|--------|------------|
| DPCP050504GE | 53mm | 53mm | 36mm | 27.5mm | 0.05kg | No |
| DPCP050504TE | 53mm | 53mm | 36mm | 27.5mm | 0.05kg | No |
| DPCP050704TE | 53mm | 65mm | 36mm | 25mm | 0.06kg | No |
| DPCP050704GE | 53mm | 65mm | 36mm | 25mm | 0.08kg | No |
| DPCP080806TE | 80mm | 82mm | 56mm | 42mm | 0.13kg | No |
| DPCP080806GE | 80mm | 82mm | 56mm | 42mm | 0.15kg | No |
| DPCP080809GE | 80mm | 82mm | 86mm | 72mm | 0.15kg | No |
| DPCP080809TE | 80mm | 82mm | 86mm | 72mm | 0.16kg | No |
| DPCP081206TE | 80mm | 120mm | 56mm | 42mm | 0.17kg | No |
| DPCP081606TE | 80mm | 160mm | 56mm | 42mm | 0.19kg | No |
| DPCP081206GE | 80mm | 120mm | 56mm | 42mm | 0.2kg | No |
| DPCP121206GE | 120mm | 122mm | 56mm | 42mm | 0.2kg | No |
| DPCP081209GE | 80mm | 120mm | 86mm | 72mm | 0.2kg | No |
| DPCP081209TE | 80mm | 120mm | 86mm | 72mm | 0.21kg | No |
| DPCP121206TE | 120mm | 122mm | 56mm | 42mm | 0.22kg | No |
| DPCP081606GE | 80mm | 160mm | 56mm | 42mm | 0.25kg | No |

| Catalog Number | Height (H) | Width (W) | Depth (D) | Max Mounting Depth | Weight | Quick Ship |
|----------------|------------|-----------|-----------|--------------------|--------|------------|
| DPCP081609TE | 80mm | 160mm | 86mm | 72mm | 0.26kg | No |
| DPCP121209TE | 120mm | 122mm | 86mm | 72mm | 0.29kg | No |
| DPCP121209GE | 120mm | 122mm | 86mm | 72mm | 0.3kg | No |
| DPCP081609GE | 80mm | 160mm | 86mm | 72mm | 0.3kg | No |
| DPCP121609GE | 120mm | 160mm | 91mm | 77.5mm | 0.35kg | No |
| DPCP121609TE | 120mm | 160mm | 91mm | 77.5mm | 0.36kg | No |
| DPCP122009GE | 120mm | 200mm | 86mm | 72mm | 0.4kg | No |
| DPCP152008GE | 150mm | 200mm | 76mm | 62mm | 0.4kg | No |
| DPCP122009TE | 120mm | 200mm | 86mm | 72mm | 0.42kg | No |
| DPCP152008TE | 150mm | 200mm | 76mm | 62mm | 0.42kg | No |
| DPCP162409GE | 160mm | 240mm | 91mm | 77.5mm | 0.6kg | No |
| DPCP162409TE | 160mm | 240mm | 91mm | 77.5mm | 0.61kg | No |
| DPCP162412TE | 160mm | 240mm | 121mm | 107.5mm | 0.74kg | No |
| DPCP162412GE | 160mm | 240mm | 121mm | 107.5mm | 0.75kg | No |
| DPCP233009GE | 230mm | 300mm | 86mm | 72.5mm | 0.95kg | No |
| DPCP233009TE | 230mm | 300mm | 86mm | 72.5mm | 0.97kg | No |
| DPCP233011GE | 230mm | 300mm | 111mm | 97.5mm | 1.1kg | No |
| DPCP233011TE | 230mm | 300mm | 111mm | 97.5mm | 1.11kg | No |

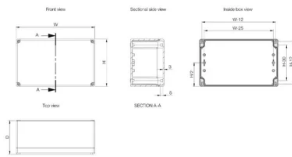

Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE