


# Panhead Screw, Torx, Self-Securing, M2.5 x 9.3

## CATALOG NUMBER

**21500-039**

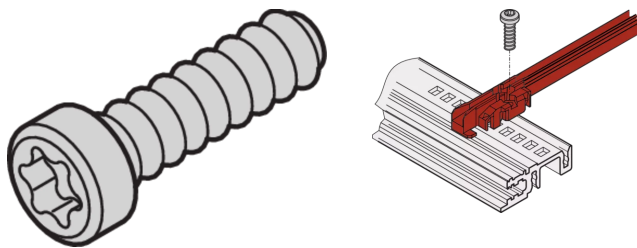

Pan head torx screws with different metric threads and lengths. With optional features like GND earthing function or precoded thread.

## CERTIFICATIONS



## FEATURES

Pan Head Screw with torx, self-locking

## PRODUCT ATTRIBUTES

Length: 9.3mm

Finish: Zinc Plated

Package Quantity: 100

Thread Size: M2.5

Material: Steel

Product Type: Screw

Type: Panhead Screw

Works With: Front Panels; Horizontal Rails, Type H; Horizontal Rails, Type R

Gross Weight: 0.037kg

## ADDITIONAL PRODUCT DETAILS

---

Torque max. 0.2 Nm.

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**